

AIDA PUSH PULL COUPLING HAN24

with power (5 pole) spring clamp + SCRJ


with fiber optic and energy  
Combicon Power/spring clamp terminal, Push Pull  
Size 24

Link to Product

Illustration



Product may differ from Image

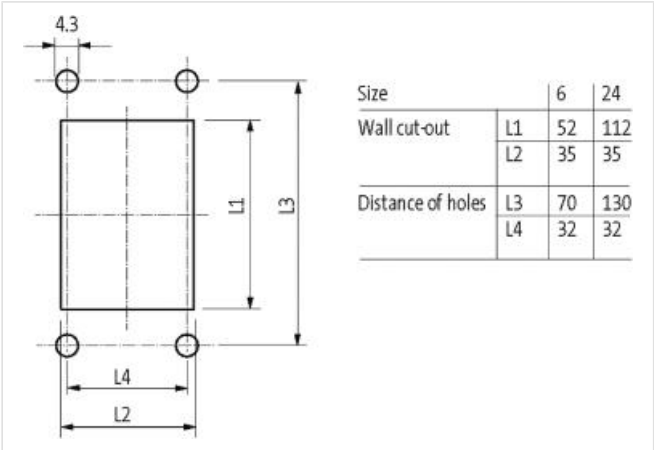

Commercial data

ECLASS-6.0	27143423
ECLASS-6.1	27143423
ECLASS-7.0	27449001
ECLASS-8.0	27449001
ECLASS-9.0	27440321
ECLASS-10.1	27440321
ECLASS-11.1	27440321
ECLASS-12.0	27440321
ETIM-5.0	EC002625
customs tariff number	85366990
GTIN	4048879031158
Packaging unit	1

Device protection | Electrical

Degree of protection (EN IEC 60529) IP65

Mechanical data | Material data

Material housing PA

Mechanical data | Mounting data

Height	146 mm
Width	58 mm
Depth	52 mm

Environmental characteristics | Climatic

Operating temperature min.	-25 °C
Operating temperature max.	70 °C