

Blind module


Blind module
Male/female
Technical data will be only guaranteed with Murrelektronik components.

Link to Product

Illustration



Product may differ from Image

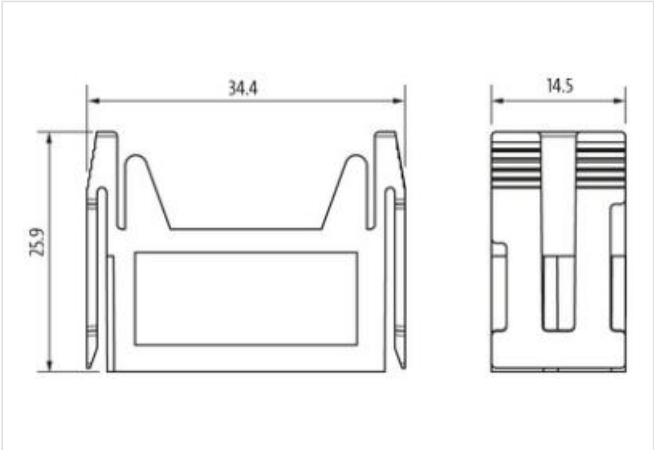

Commercial data	
ECLASS-6.0	27143424
ECLASS-6.1	27261290
ECLASS-7.0	27440290
ECLASS-8.0	27440290
ECLASS-9.0	27440292
ECLASS-10.1	27440292
ECLASS-11.1	27440292
ECLASS-12.0	27440292
ETIM-5.0	EC000438
customs tariff number	85389099
GTIN	4048879641517
Packaging unit	5
Installation Connection	
Mating cycles min.	500
Device protection Electrical	
Pollution Degree	3
Mechanical data	
Holding force modules min.	150 N
Mechanical data Material data	
Combustibility class (UL94)	V-0
Material housing	PA
Mechanical data Mounting data	
Number of module slots	1
Height	25,9 mm
Width	15,4 mm
Depth	34,4 mm

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	125 °C
Climatic category (EN IEC 60068-1)	40/125/10