


Shielded male module, 2-pole

50 V, 10 A

Male  
2-pole  
Koax  
Technical data will be only guaranteed with Murrelektronik components.

Link to Product

Illustration

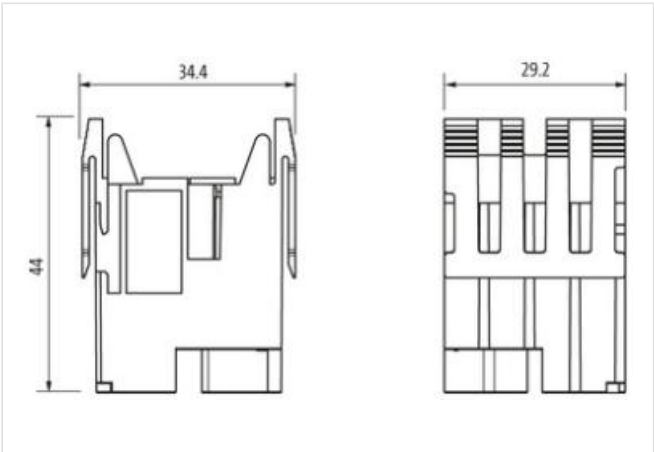

Product may differ from Image

Commercial data

ECLASS-6.0	27143424
ECLASS-6.1	27261204
ECLASS-7.0	27440204
ECLASS-8.0	27440204
ECLASS-9.0	27440217
ECLASS-10.1	27440217
ECLASS-11.1	27440217
ECLASS-12.0	27440217
ETIM-5.0	EC000438
customs tariff number	85389099
GTIN	4048879641845
Packaging unit	5

Installation | Connection

Gender	male
Mating cycles min.	500

Installation | Pin assignment

No. of poles	2
--------------	---

Device protection | Electrical

Pollution Degree	3
Overvoltage category (EN 60664-1)	I

Mechanical data | Material data

Combustibility class (UL94)	V-0
Material housing	PA

Mechanical data | Mounting data

Number of module slots	2
Height	44 mm
Width	29,2 mm
Depth	34,4 mm
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-40 °C
Operating temperature max.	125 °C
Climatic category (EN IEC 60068-1)	40/125/10