


RJ45 module - male, adapter

Male
RJ45
Adapter for industry plug connectors
Technical data will be only guaranteed with Murrelektronik components.
The clip 70MH-ZZ100-0000000 is needed (2×)

Link to Product

Illustration

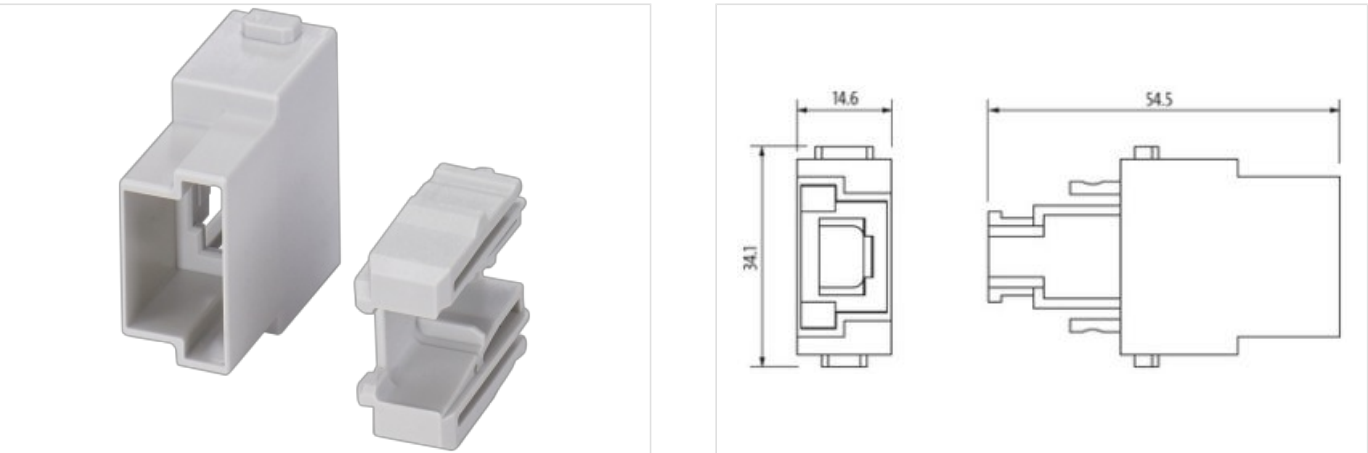

Product may differ from Image



| Commercial data | |
|--------------------------------|---------------|
| ECLASS-6.0 | 27143424 |
| ECLASS-6.1 | 27261204 |
| ECLASS-7.0 | 27440204 |
| ECLASS-8.0 | 27440204 |
| ECLASS-9.0 | 27440204 |
| ECLASS-10.1 | 27440204 |
| ECLASS-11.1 | 27440204 |
| ECLASS-12.0 | 27440204 |
| ETIM-5.0 | EC000437 |
| customs tariff number | 85389099 |
| GTIN | 4048879664080 |
| Packaging unit | 1 |
| Electrical data Supply | |
| Operating voltage AC | 50 V |
| Operating voltage DC | 50 V |
| Industrial communication | |
| Transfer parameters | CAT5e |
| Installation Connection | |
| Gender | male |
| Mating cycles min. | 500 |
| Device protection Electrical | |

| | |
|-----------------------------------|--------|
| Pollution Degree | 3 |
| Rated surge voltage | 0,8 kV |
| Overvoltage category (EN 60950-1) | III |

Mechanical data | Material data

| | |
|-----------------------------|-----|
| Combustibility class (UL94) | V-0 |
| Material housing | PC |

Mechanical data | Mounting data

| | |
|------------------------|---------|
| Number of module slots | 1 |
| Height | 41 mm |
| Width | 34,1 mm |
| Depth | 14,6 mm |

Environmental characteristics | Climatic

| | |
|----------------------------|--------|
| Operating temperature min. | -40 °C |
| Operating temperature max. | 70 °C |