

## B10 frame (male) for 3 modules

A...C

B10

Frame



Male

for 3 modules

Technical data will be only guaranteed with Murrelektronik components.

### [Link to Product](#)

#### Illustration

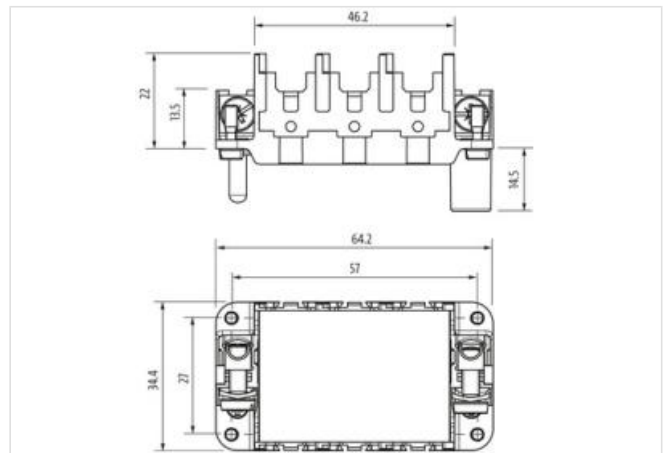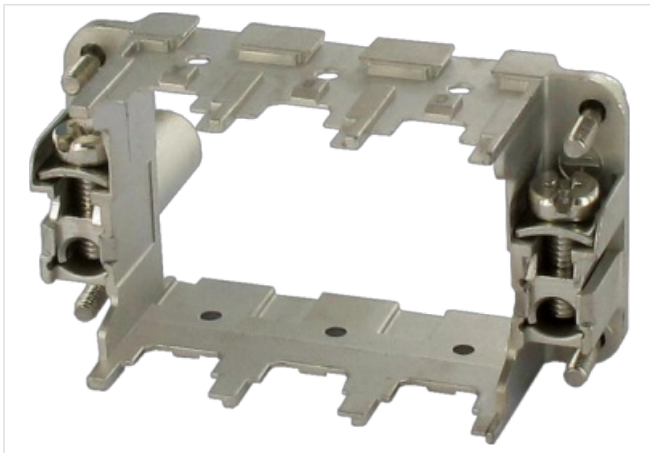

Product may differ from Image

#### Technical Data

No. of poles	2 PE
Connection	Screw terminal
Connection cross section	1...6 mm <sup>2</sup> (AWG 18...10)
Mating cycles (frame)	min. 500
Insertion and withdrawal force	< 60 N
Mating cycles (safety element)	min. 20
Holding force (PE contact)	250 N
Contact resistance	≤ 5 mΩ
Holding force (modules)	≥ 300 N (when stuck) ≥ 600 N (when pulling)

#### General data

Material contact	Brass
Material contact surface	Ni
Temperature range	-40...+125 °C
No. of module positions	3
Flammability class	V-0 (acc. to UL 94)
Material safety element	PC GF
Size	B10
Material frame	Zinc die casting, nickel-plated
Climatic category	40/125/10
Frame type	Male
Dimensions H×W×D	36.5×34.4×64.2 mm