

MICO IP67 electronic circuit protection, 4 Channels, 2A

IN: 24 V DC OUT: 24 V DC / 2 A CL2 / Expandable

MICO67 4.2 CL2

4 × M12, A-coded NEC CL2, (2 A)

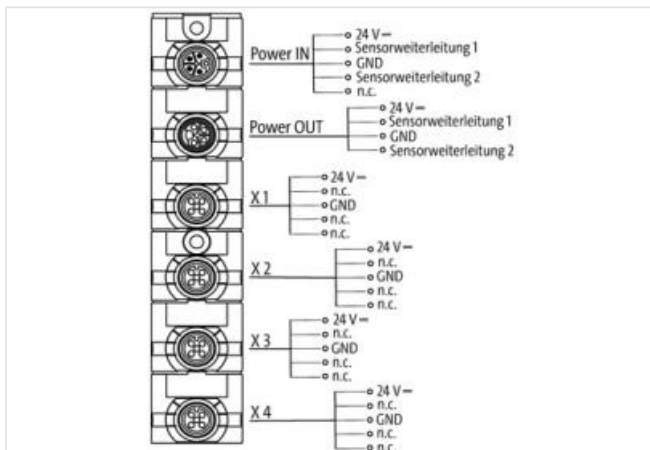
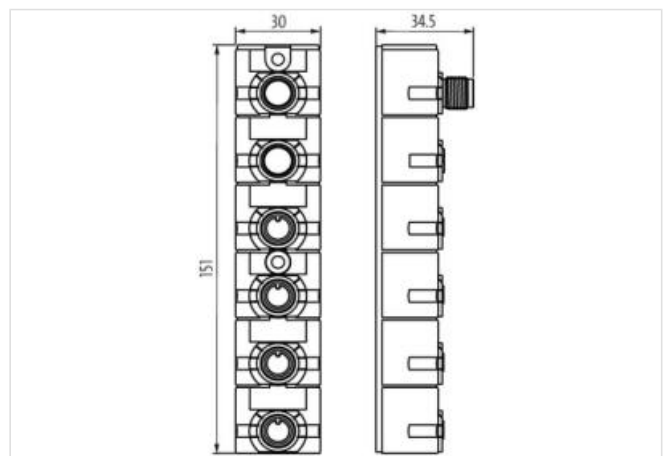
Voltage IN and transmission via M12, L-coded (16 A)

24 V/16 A

24 V/2 A

LED port diagnostic

Limitation of the 4 voltage taps to 2 A (M12, A-coded)

[Link to Product](#)
Illustration


Product may differ from Image


Commercial data

ECLASS-11.1	27371802
customs tariff number	85363010
GTIN	4048879852272

Packaging unit 1

Device protection | Electrical

Degree of protection (EN IEC 60529) IP65, IP67

Environmental characteristics | Climatic

Operating temperature min.	-25 °C
Operating temperature max.	45 °C
Storage temperature min.	-25 °C
Storage temperature max.	70 °C