

SUPPRESSOR FOR CONTACTORS

RC, 400 VAC/DC 50 VA/W



400 V AC/DC

RC

For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

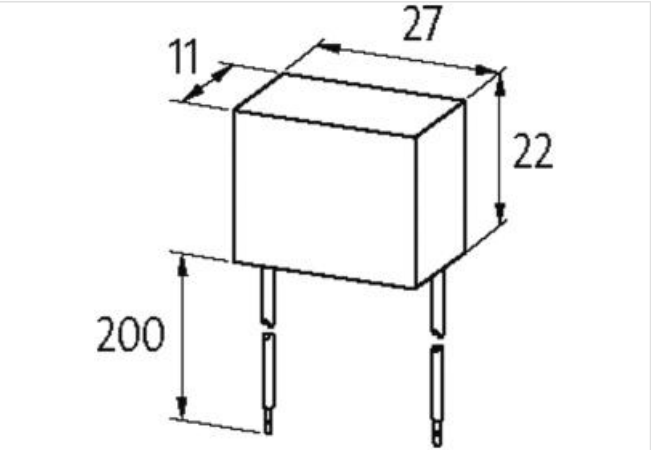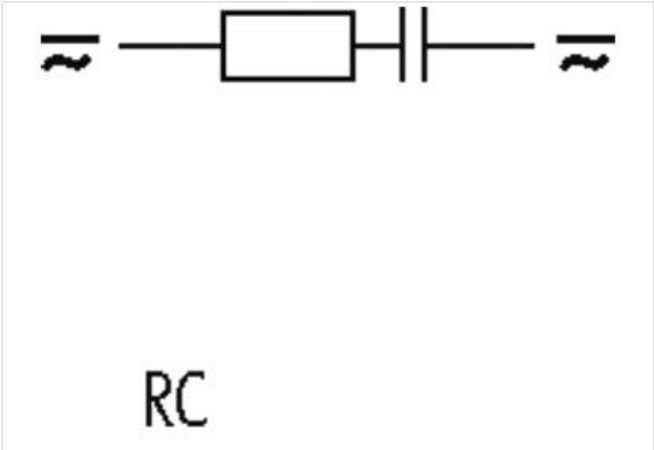

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
customs tariff number	85363010
GTIN	4048879020305
Packaging unit	1

Compatibility | Compatible with

Appropriate contactors	universal
------------------------	-----------

Electrical data

Damping factor	1.5× UN
Holding power max.	50 W

Electrical data | Input

Input voltage AC min.	240 V
Input voltage AC max.	400 V
Input voltage DC min.	240 V
Input voltage DC max.	400 V

Installation | Connection

Connection information	flexible connection wires
------------------------	---------------------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Combustibility class housing (UL94)	V-0
Material housing	Plastic

Mechanical data | Mounting data

Height	22 mm
Width	27 mm
Depth	11 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C