

MOTOR SUPPRESSOR

RC, 3x400VAC/10kW


3× 400 V AC

RC

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

Link to Product

Illustration

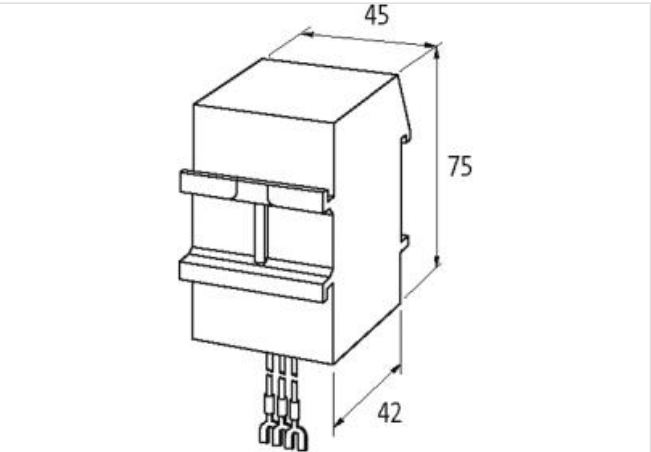

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
customs tariff number	85363010
GTIN	4048879019651
Packaging unit	1
<b>Electrical data   Supply</b>	
Power frequency	50 ... 60 Hz
<b>Electrical data   Input</b>	
Input voltage AC	400 V
<b>Installation</b>	
Connection cross-section stranded/fine-stranded min.	0,5 mm <sup>2</sup>
<b>Installation   Connection</b>	
Connection information	Einzellitzen mit selbstsicherndem Gabelkabelschuh M4
Length single strands	250 mm
<b>Device protection   Media</b>	
Flame resistance	flame retardant
<b>Mechanical data   Material data</b>	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Material potting compound	2-component epoxy
<b>Mechanical data   Mounting data</b>	
Height	75 mm
Width	45 mm
Depth	42 mm
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C