

MOTOR SUPPRESSOR

RC, 3x400VAC/4kW

3× 400 V AC



RC

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

For DIN-rail mounting use 2×Art.-No. 20900 adapter feet  
approx. 500 mm, PVC cable 3× 0.75 mm²

Link to Product

Illustration

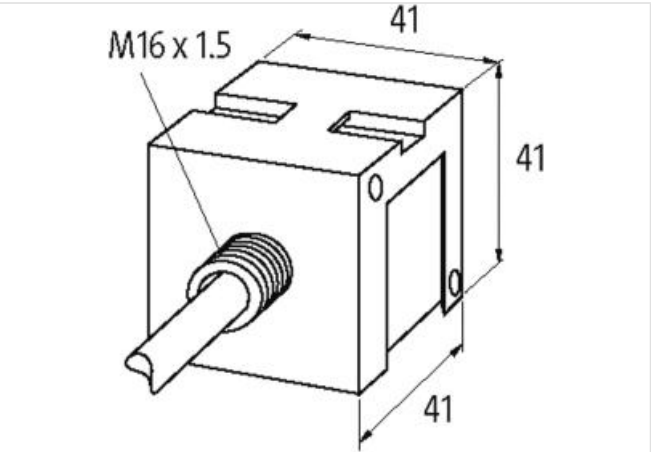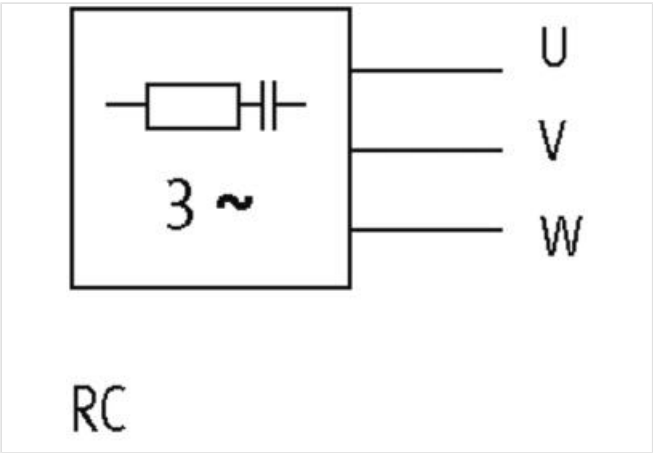

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013

ECLASS-9.0	27371013
ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
customs tariff number	85363010
GTIN	4048879019507
Packaging unit	1
<b>Electrical data   Supply</b>	
Power frequency	50 ... 60 Hz
<b>Electrical data   Input</b>	
Input voltage AC	400 V
<b>Installation</b>	
Connection cross section max.	0,75 mm²
<b>Installation   Connection</b>	
Family construction form	free cable end
<b>Installation   Pin assignment</b>	
No. of poles	3
<b>Device protection   Media</b>	
Flame resistance	flame retardant
<b>Mechanical data   Material data</b>	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Material potting compound	2-component epoxy
<b>Mechanical data   Mounting data</b>	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Height	41 mm
Width	41 mm
Depth	41 mm
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C