

MOTOR SUPPRESSOR



RC, 3x400...575VAC/4kW

3× 400 V AC  
3× 575 V AC  
RC

For DIN-rail mounting use Art.-No. 20900 adapter feet  
Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

Link to Product

Illustration

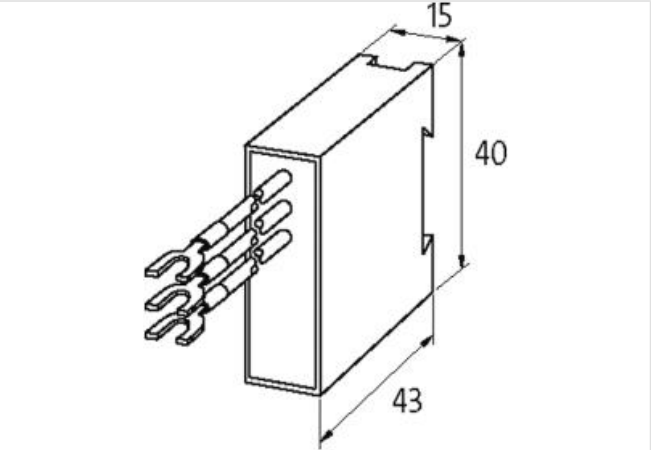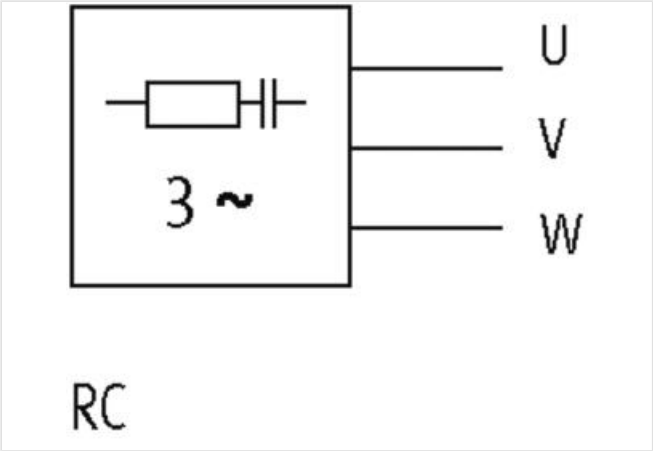

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013

ECLASS-9.0	27371013
ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
customs tariff number	85363010
GTIN	4048879019453
Packaging unit	1

#### Electrical data | Supply

Power frequency	50 ... 60 Hz
-----------------	--------------

#### Electrical data | Input

Input voltage AC	575 V
------------------	-------

#### Installation

Connection cross-section stranded/fine-stranded min.	0,35 mm²
--	----------

#### Installation | Connection

Connection information	Einzellitzen mit selbstsicherndem Gabelkabelschuh M4
Length single strands	200 mm

#### Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

#### Mechanical data | Material data

Combustibility class housing (UL94)	V-0
Material housing	Plastic
Material potting compound	2-component epoxy

#### Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Height	43 mm
Width	15 mm
Depth	40 mm

#### Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C