

MOTOR SUPPRESSOR



Varistor, 3x400VAC/4kW

3× 400 V AC  
VDR  
isolated M6  
PG9

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

Link to Product

Illustration

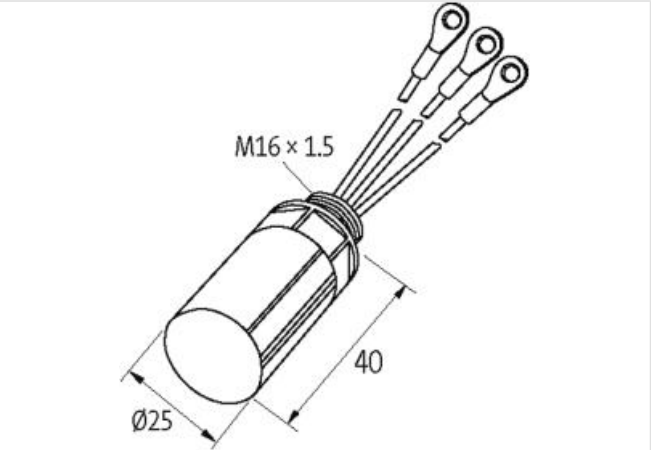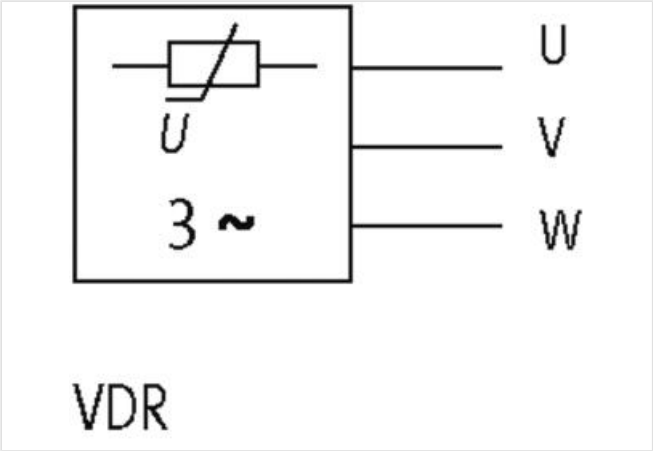

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27371013 |
| ECLASS-6.1      | 27371013 |
| ECLASS-7.0      | 27371013 |
| ECLASS-8.0      | 27371013 |

|                       |               |
|-----------------------|---------------|
| ECLASS-9.0            | 27371013      |
| ECLASS-10.1           | 27371013      |
| ECLASS-11.1           | 27371013      |
| ECLASS-12.0           | 27371013      |
| ETIM-5.0              | EC000197      |
| customs tariff number | 85363010      |
| GTIN                  | 4048879019316 |
| Packaging unit        | 1             |

#### Electrical data | Supply

|                 |               |
|-----------------|---------------|
| Power frequency | 10 ... 400 Hz |
|-----------------|---------------|

#### Electrical data | Input

|                  |       |
|------------------|-------|
| Input voltage AC | 400 V |
|------------------|-------|

#### Installation

|                               |                     |
|-------------------------------|---------------------|
| Connection cross section max. | 0,5 mm <sup>2</sup> |
|-------------------------------|---------------------|

#### Installation | Connection

|                        |                |
|------------------------|----------------|
| Connection information | Single strands |
| Length single strands  | 100 mm         |
| Ring terminals         | M6isolated     |

#### Device protection | Media

|                  |                 |
|------------------|-----------------|
| Flame resistance | flame retardant |
|------------------|-----------------|

#### Mechanical data | Material data

|                                     |                   |
|-------------------------------------|-------------------|
| Combustibility class housing (UL94) | V-0               |
| Material housing                    | Plastic           |
| Material potting compound           | 2-component epoxy |

#### Mechanical data | Mounting data

|                            |                  |
|----------------------------|------------------|
| Mounting method            | inserted         |
| Suitable for mounting type | Motorklemmkasten |
| Height                     | 25 mm            |
| Width                      | 25 mm            |
| Depth                      | 40 mm            |

#### Environmental characteristics | Climatic

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 60 °C  |