



**MOTOR SUPPRESSOR**

Varistor, 3x575VAC/20kW

3× 575 V AC  
VDR-(1) per phase  
Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)

Illustration

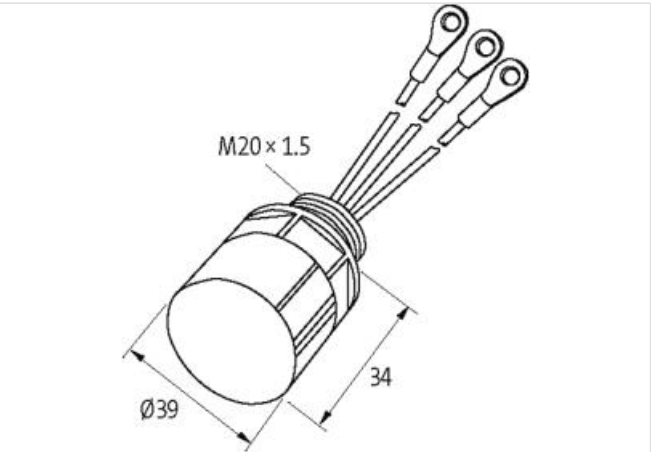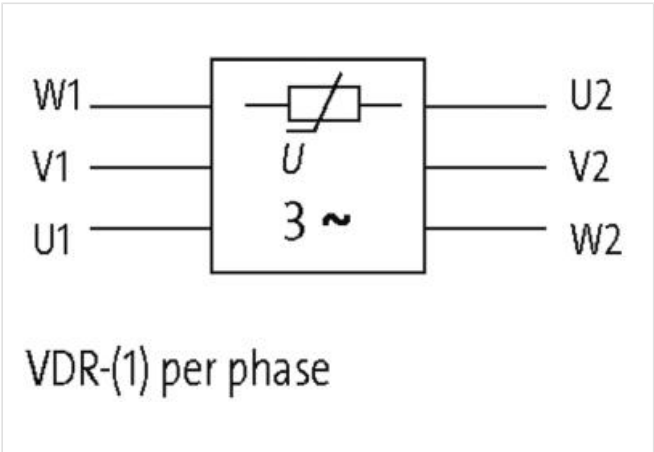

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
customs tariff number	85363010
GTIN	4048879019088
Packaging unit	1

**Electrical data | Supply**

Power frequency	10 ... 400 Hz
-----------------	---------------

**Electrical data | Input**

Input voltage AC	575 V
------------------	-------

**Installation**

Connection cross section max.	1 mm <sup>2</sup>
-------------------------------	-------------------

**Installation | Connection**

Connection information	Single strands
Length single strands	150 mm
Ring terminals	M6isolated

**Device protection | Media**

Flame resistance	flame retardant
------------------	-----------------

**Mechanical data | Material data**

Combustibility class housing (UL94)	V-0
Material housing	Plastic
Material potting compound	2-component epoxy

**Mechanical data | Mounting data**

Mounting method	inserted
Suitable for mounting type	Motorklemmkasten
Height	39 mm
Width	39 mm
Depth	44 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	60 °C