

MOTOR SUPPRESSOR

RC, 3x575VAC/5,5kW



3× 575 V AC

RC

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)

Illustration

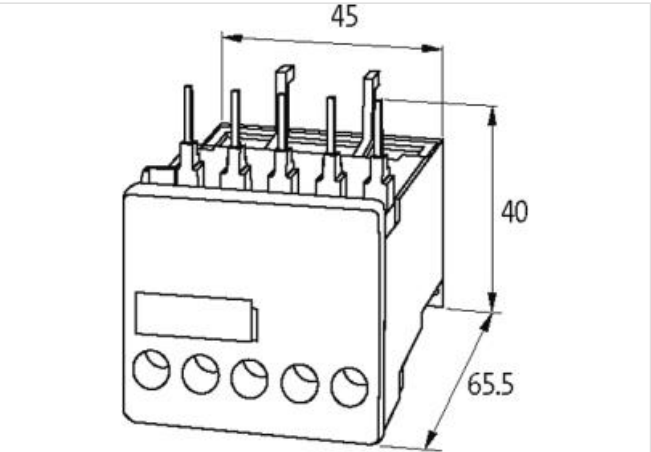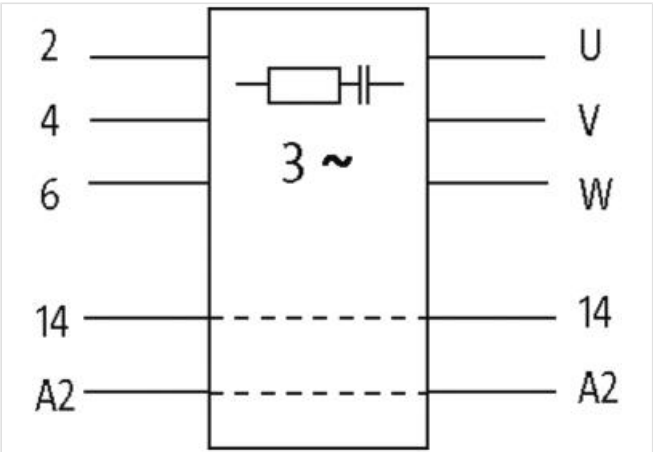

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
customs tariff number	85363010
GTIN	4048879018869
Packaging unit	1
<b>Compatibility   Compatible with</b>	
Appropriate contactors	3 RT 20, Siemens 3 RT 10
<b>Electrical data   Supply</b>	
Power frequency	50 ... 60 Hz
<b>Electrical data   Input</b>	
Input voltage AC	575 V
<b>Installation   Connection</b>	
Connection information	fits directly into SIRIUS contactors, size 00
<b>Device protection   Media</b>	
Flame resistance	flame retardant
<b>Mechanical data   Material data</b>	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
<b>Mechanical data   Mounting data</b>	
Height	40 mm
Width	45 mm
Depth	65,5 mm
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C