

SIEMENS CONTACTOR SUPPRESSOR

Diode, 0...240VDC



48 V AC/DC

Diode

For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

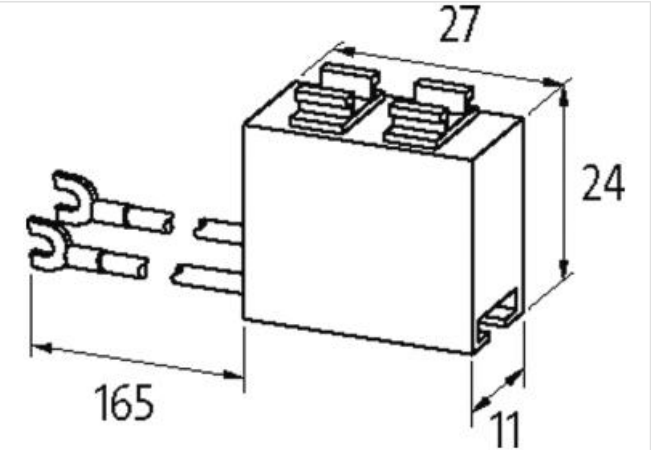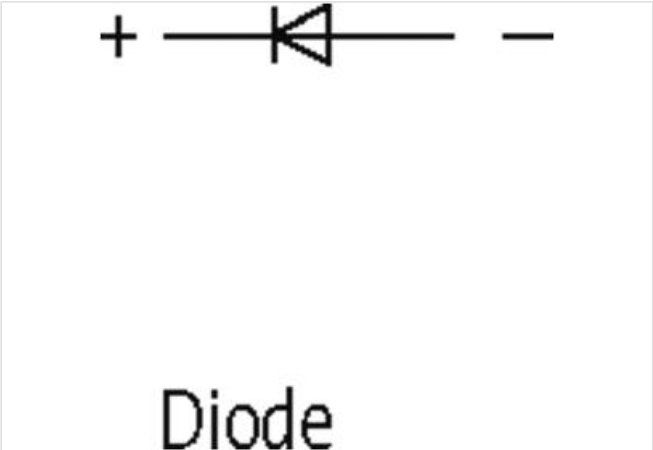

Product may differ from Image



| Commercial data | |
|-----------------|----------|
| ECLASS-6.0 | 27371013 |
| ECLASS-6.1 | 27371013 |
| ECLASS-7.0 | 27371013 |
| ECLASS-8.0 | 27371013 |
| ECLASS-9.0 | 27371013 |
| ECLASS-10.1 | 27371013 |

| | |
|---|---|
| ECLASS-11.1 | 27371013 |
| ECLASS-12.0 | 27371013 |
| ETIM-5.0 | EC002498 |
| customs tariff number | 85363010 |
| GTIN | 4048879018494 |
| Packaging unit | 1 |
| Compatibility Compatible with | |
| Appropriate contactors | 3 TH 3/4/8; 3 TF 30...45; 3 TB 40...3 TB 44 |
| Electrical data | |
| Damping factor | 1.5× UN |
| Holding power max. | 15 W |
| Electrical data Input | |
| Input voltage DC min. | 12 V |
| Input voltage DC max. | 250 V |
| Installation Connection | |
| Connection information | self-securing cable forks |
| Device protection Media | |
| Flame resistance | flame retardant |
| Mechanical data Material data | |
| Combustibility class housing (UL94) | V-0 |
| Material housing | Plastic |
| Mechanical data Mounting data | |
| Height | 11 mm |
| Width | 27 mm |
| Depth | 24 mm |
| Environmental characteristics Climatic | |
| Operating temperature min. | -20 °C |
| Operating temperature max. | 70 °C |