



TELEMECANIQUE CONTACTOR SUPPRESSOR

Diode, 0...240VDC

24...240 V DC
Diode
For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

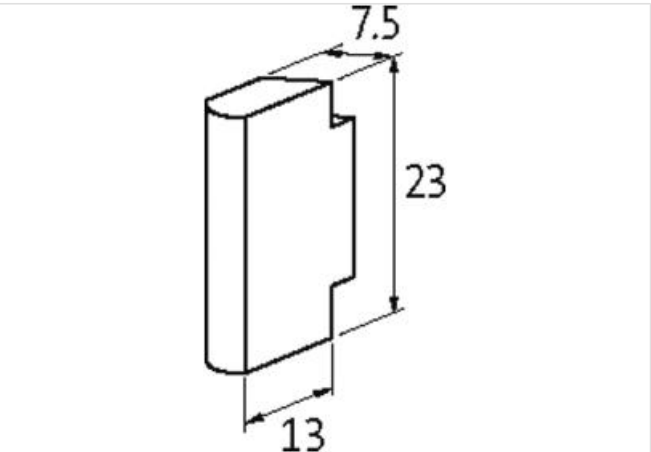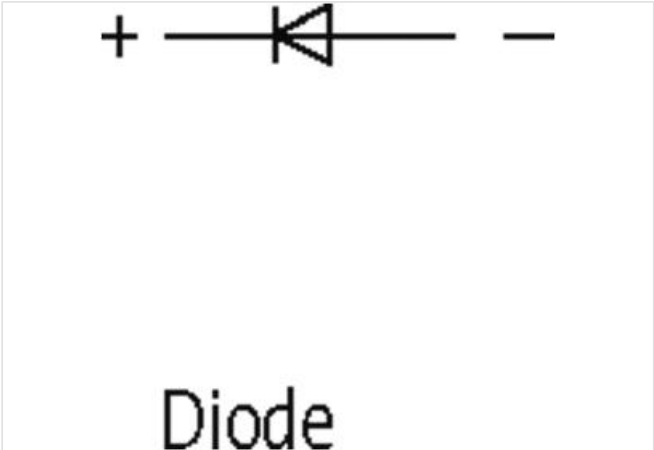

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
customs tariff number	85363010
GTIN	4048879018098
Packaging unit	1

Compatibility | Compatible with

Appropriate contactors	A 9...A 16
------------------------	------------

Electrical data

Damping factor	1.5× UN
----------------	---------

Electrical data | Input

Input voltage DC	220 V
------------------	-------

Installation | Connection

Connection information	Plug contact
------------------------	--------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Combustibility class housing (UL94)	V-0
-------------------------------------	-----

Material housing	Plastic
------------------	---------

Mechanical data | Mounting data

Height	13 mm
--------	-------

Width	23 mm
-------	-------

Depth	7,5 mm
-------	--------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
----------------------------	--------

Operating temperature max.	70 °C
----------------------------	-------