



SIEMENS CONTACTOR SUPPRESSOR

Diode, 0...240VDC

24...240 V DC
Diode
For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

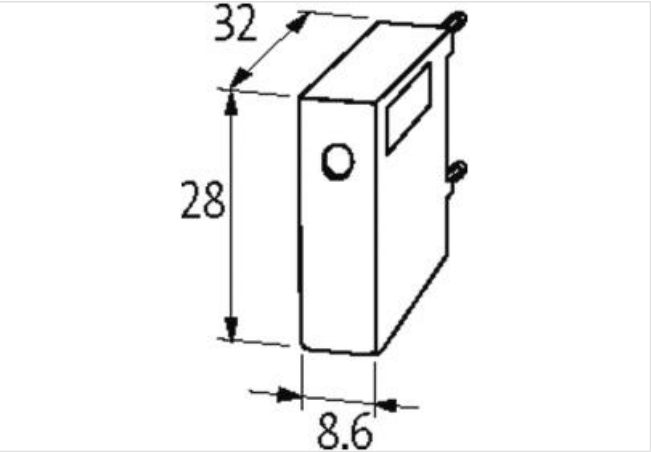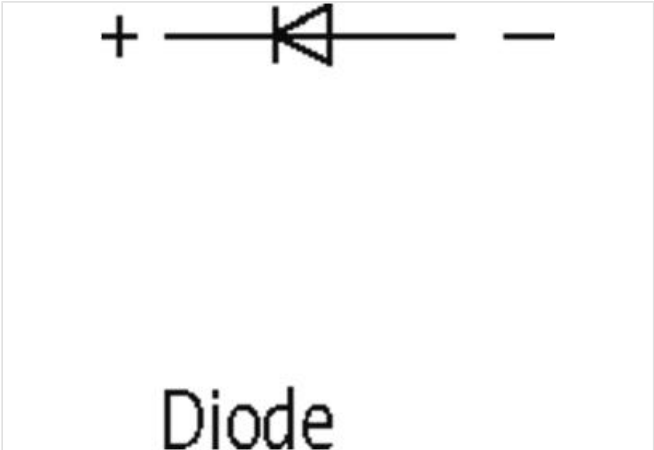

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
customs tariff number	85363010
GTIN	4048879017640
Packaging unit	1

Compatibility | Compatible with

Appropriate contactors	3 RH 1/11; 3 RT 1/3 RH1; 3 RT 1/10.15...10.17
------------------------	---

Electrical data | Input

Input voltage DC min.	12 V
Input voltage DC max.	240 V

Mechanical data | Mounting data

Height	28 mm
Width	8,6 mm
Depth	32 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C