



SV-SUB D 15 .-KL FOR SIGNAL TRANSFER

125 VAC/DC / 2 A

Female connector
15-pole
Screw terminals

[Link to Product](#)

Illustration

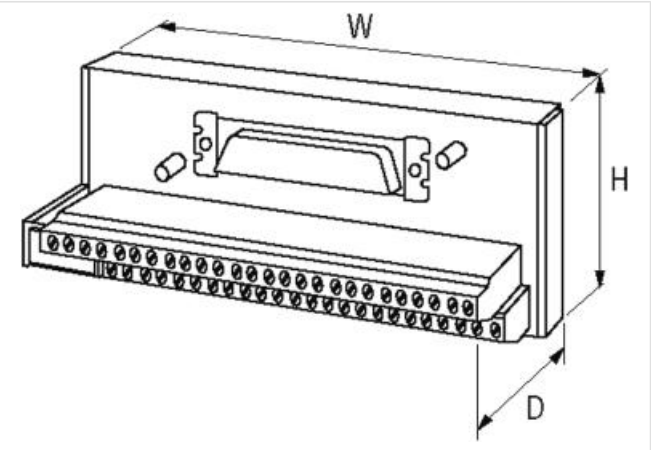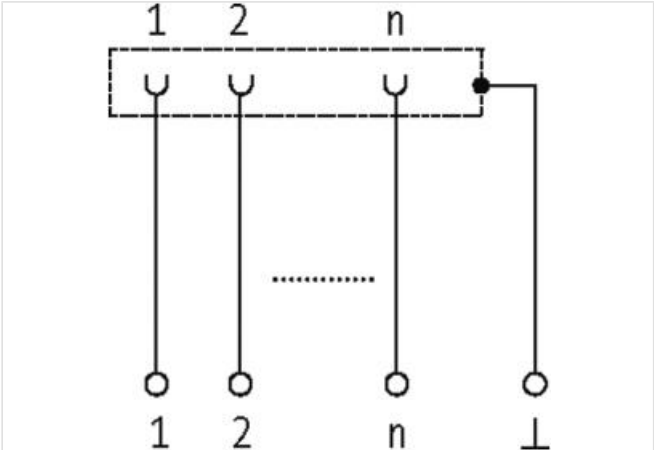

Product may differ from Image



| Commercial data | |
|-----------------|----------|
| ECLASS-6.0 | 27143424 |
| ECLASS-6.1 | 27260708 |
| ECLASS-7.0 | 27141152 |
| ECLASS-8.0 | 27141152 |
| ECLASS-9.0 | 27141152 |
| ECLASS-10.1 | 27141152 |

| | |
|---|--|
| ECLASS-11.1 | 27141152 |
| ECLASS-12.0 | 27141152 |
| ETIM-5.0 | EC001283 |
| customs tariff number | 85366990 |
| GTIN | 4048879026482 |
| Packaging unit | 1 |
| Electrical data Supply | |
| Operating voltage AC | 125 V |
| Operating voltage DC | 150 V |
| Operating current max. | 2 A |
| Device protection Electrical | |
| Overvoltage category (EN 60664-1) | II |
| Mechanical data Mounting data | |
| Mounting method | geschnappt |
| Suitable for mounting type | mounting rail, (EN 60715) |
| Height | 63 mm |
| Width | 75 mm |
| Depth | 48 mm |
| Looking techniques | Standard UNC 4-40 screw thread bolt (EN 60807) |
| Environmental characteristics Climatic | |
| Operating temperature min. | -20 °C |
| Operating temperature max. | 70 °C |