


MA5I67 INSTALLATION TECHNOLOGY

Connection 2x profile- to 2x profile cable


MA5I67 connection
2x on 2x profile cable

[Link to Product](#)

Illustration

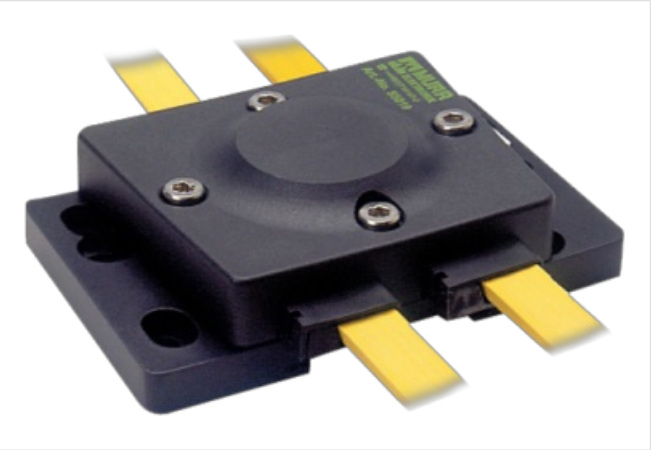

Product may differ from Image

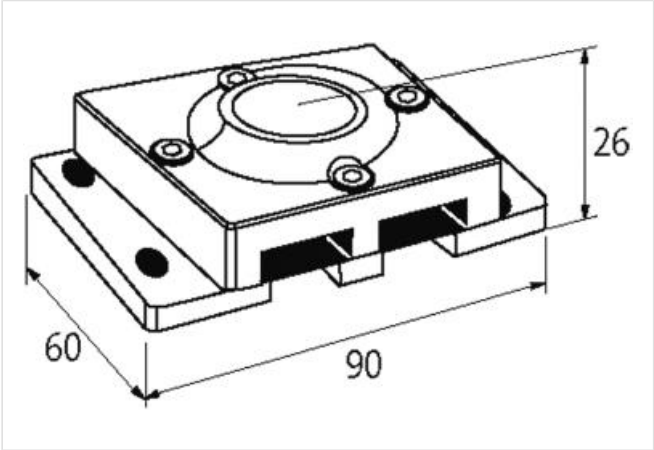

| Commercial data | |
|-------------------------------------|---------------------------|
| ECLASS-6.0 | 27400209 |
| ECLASS-6.1 | 27279219 |
| ECLASS-7.0 | 27279219 |
| ECLASS-8.0 | 27279219 |
| ECLASS-9.0 | 27440108 |
| ECLASS-10.1 | 27440111 |
| ECLASS-11.1 | 27440111 |
| ECLASS-12.0 | 27440111 |
| ETIM-5.0 | EC001583 |
| customs tariff number | 85369010 |
| GTIN | 4048879052184 |
| Packaging unit | 1 |
| Electrical data Supply | |
| Operating voltage DC max. | 36 V |
| Total current max. | 8 A |
| Device protection Electrical | |
| Degree of protection (EN IEC 60529) | IP67 |
| Insulation strength ASI/Power | 200 V |
| Mechanical data Mounting data | |
| Mounting method | screwed, geschnappt |
| Suitable for mounting type | mounting rail, (EN 60715) |
| Height | 90 mm |

| | |
|---|------------|
| Width | 74 mm |
| Depth | 26 mm |
| Environmental characteristics Climatic | |
| Operating temperature min. | -20 °C |
| Operating temperature max. | 60 °C |
| Storage temperature min. | -40 °C |
| Storage temperature max. | 80 °C |
| Conformity | |
| Product standard | EN 60664-1 |