



**MASI67 INSTALLATION TECHNOLOGY**

Converter 2x profile cable to 7/8" male

MASI67 converter  
2x profile cable to 7/8" (male)  
Connection cables are in the online shop under "Connection Technology".

**[Link to Product](#)**

**Illustration**

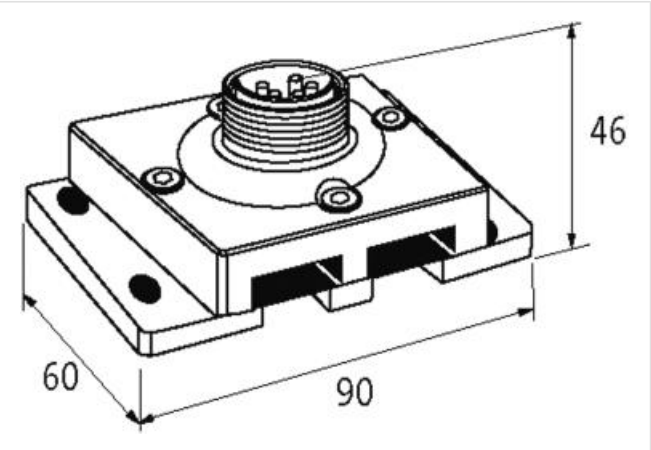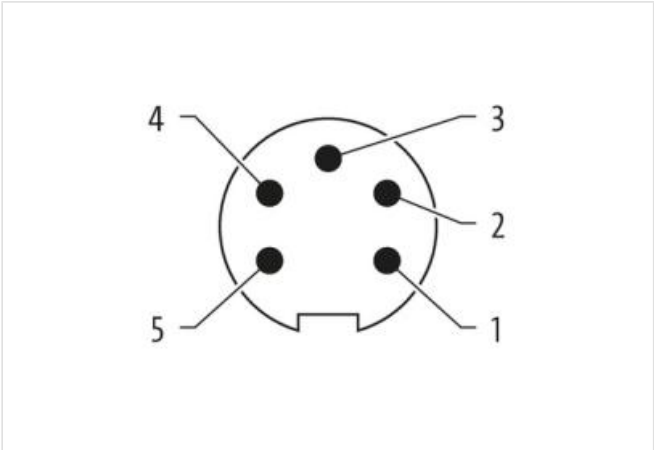

Product may differ from Image



Commercial data	
ECLASS-6.0	27400209
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440111

ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC001583
customs tariff number	85369010
GTIN	4048879052153
Packaging unit	1
<b>Electrical data   Supply</b>	
Operating voltage DC max.	36 V
Total current max.	8 A
<b>Device protection   Electrical</b>	
Degree of protection (EN IEC 60529)	IP67
Insulation strength ASI/Power	200 V
<b>Mechanical data   Mounting data</b>	
Mounting method	screwed, geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	90 mm
Width	74 mm
Depth	46 mm
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
<b>Conformity</b>	
Product standard	EN 60664-1
<b>Connection type 1</b>	
Family construction form	7/8"
Gender	male
Color contact carrier	black
No. of poles	5
PIN 1	AS-i +
PIN 2	AS-i -
PIN 3	n.c.
PIN 4	24 V DC
PIN 5	0 V