

CUBE67 ACCESSORIES

System interface connector


M12
Male straight
Internal system connection

Link to Product

Illustration



Product may differ from Image

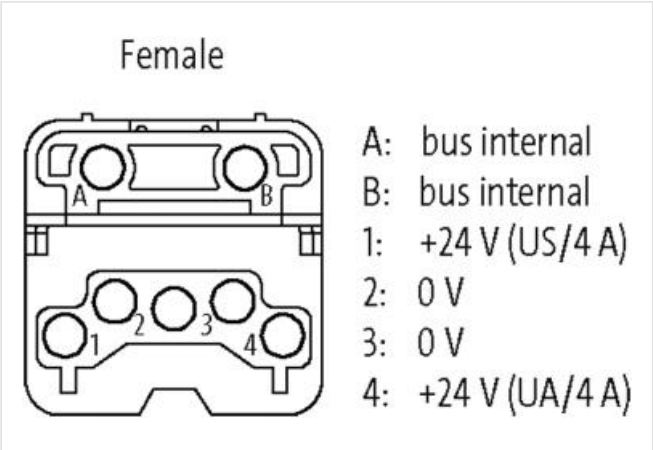

Commercial data	
ECLASS-6.0	27242692
ECLASS-6.1	27242692
ECLASS-7.0	27242692
ECLASS-8.0	27242692
ECLASS-9.0	27242692
ECLASS-10.1	27242692
ECLASS-11.1	27242692
ECLASS-12.0	27242692
ETIM-5.0	EC001583
customs tariff number	85366990
GTIN	4048879047906
Packaging unit	1
Electrical data Supply	
Operating voltage DC	24 V
Operating current max.	4 A
Installation Connection	
Connection information	Han-Brid®, 6-polig
Family construction form	M12
Gender	female
Mating cycles min.	500
Installation Pin assignment	
No. of poles	6
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65
Mechanical data Mounting data	

Height	74 mm
Width	33,5 mm
Depth	28,5 mm
Environmental characteristics Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	85 °C