

CUBE67 ACCESSORIES

System interface connector


M12
Female straight
Internal system connection
with mounting socket
Flange, hole spacing 30 mm, bore 3.3 mm

Link to Product

Illustration



Product may differ from Image

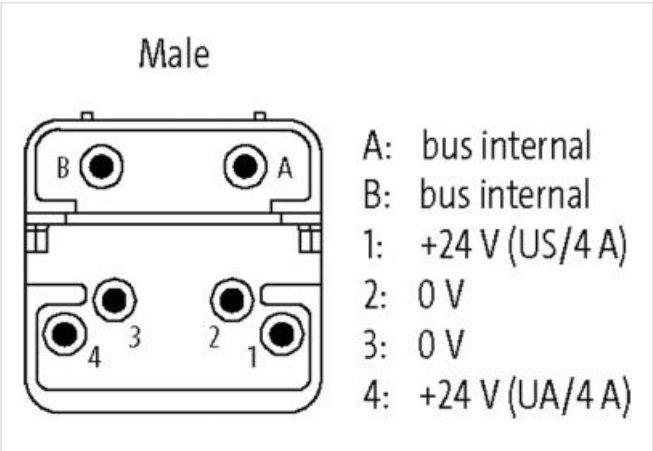

Commercial data	
ECLASS-6.0	27242692
ECLASS-6.1	27242692
ECLASS-7.0	27242692
ECLASS-8.0	27242692
ECLASS-9.0	27242692
ECLASS-10.1	27242692
ECLASS-11.1	27242692
ECLASS-12.0	27242692
ETIM-5.0	EC001583
customs tariff number	85366990
GTIN	4048879047890
Packaging unit	1
Electrical data Supply	
Operating voltage DC	24 V
Operating current max.	4 A
Installation Connection	
Connection information	Han-Brid®, 6-polig
Family construction form	M12
Gender	female
Mating cycles min.	500
Installation Pin assignment	
No. of poles	6
Device protection Electrical	

Degree of protection (EN IEC 60529) IP65

Mechanical data | Mounting data

Height	80,5 mm
Width	40 mm
Depth	40 mm

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	85 °C