

Xenterra 5TX unmanaged Switch wallmounted 5 Port 100Mbit


5 port unmanaged switch  
Key-hole mounting/screwable  
Connection cables are in the online shop under "Connection Technology".

Link to Product

Illustration



Product may differ from Image

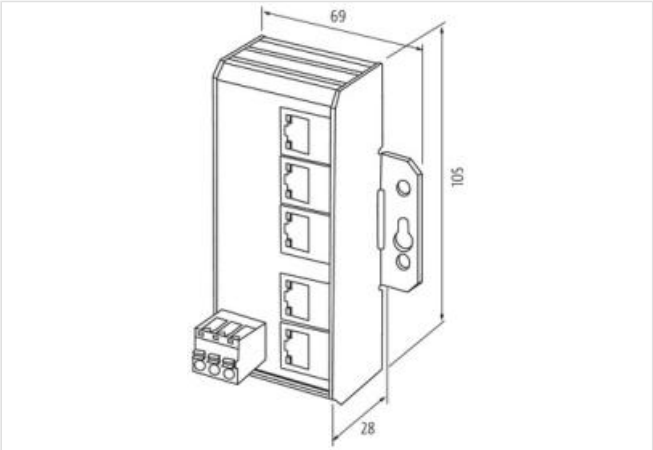

| Commercial data                                   |               |
|---|---------------|
| ECLASS-6.1  | 19170106      |
| ECLASS-7.0  | 19170106      |
| ECLASS-8.0  | 19170106      |
| ECLASS-9.0  | 19170402      |
| ECLASS-10.1                                       | 19170402      |
| ECLASS-11.1                                       | 19170402      |
| ECLASS-12.0                                       | 19170402      |
| customs tariff number                             | 85176200      |
| GTIN  | 4048879830287 |
| Packaging unit                                    | 1             |
| Electrical data   Supply                          |               |
| Operating voltage AC min.                         | 8 V           |
| Operating voltage AC max.                         | 28 V          |
| Operating voltage DC min.                         | 9 V           |
| Operating voltage DC max.                         | 36 V          |
| Industrial communication                          |               |
| Data transmission rate max.                       | 100 MBit/s    |
| Industrial communication   Ethernet functionality |               |
| Auto-crossover                                    | yes           |
| Auto-negotiation                                  | yes           |
| duplex  | Full duplex   |
| Switch type                                       | unmanaged     |

VLAN unmanaged (IEEE 802.1Q)      yes

#### Diagnostics

|               |                                  |
|---------------|----------------------------------|
| Alarm contact | no                               |
| Diagnostic    | No voltage                       |
| LED display   | Ethernet connection/data traffic |

#### Device protection | Electrical

|                                     |      |
|-------------------------------------|------|
| Degree of protection (EN IEC 60529) | IP20 |
|-------------------------------------|------|

#### Mechanical data | Material data

|                  |       |
|------------------|-------|
| Color housing    | black |
| Material housing | Metal |

#### Mechanical data | Mounting data

|                            |                        |
|----------------------------|------------------------|
| Mounting method            | screwed                |
| Suitable for mounting type | Schlüssellochabhängung |
| Height                     | 105 mm                 |
| Width                      | 69 mm                  |
| Depth                      | 28 mm                  |

#### Environmental characteristics | Climatic

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -40 °C |
| Operating temperature max. | 70 °C  |
| Storage temperature min.   | -40 °C |
| Storage temperature max.   | 85 °C  |

#### Connection type 1

|                          |        |
|--------------------------|--------|
| Connection type 1        | 5      |
| Family construction form | RJ45   |
| Gender                   | female |
| Color contact carrier    | black  |
| No. of poles             | 8      |
| PIN 1                    | TD +   |
| PIN 2                    | TD -   |
| PIN 3                    | RD +   |
| PIN 4                    | n.c.   |
| PIN 5                    | n.c.   |
| PIN 6                    | RD -   |
| PIN 7                    | n.c.   |
| PIN 8                    | n.c.   |