



IR RELAY SOCKET MODULES

Product discontinued, no alternative

for industrial relays  
4 NO/NC contacts  
0...230 V AC/DC  
without components

[Link to Product](#)

Illustration

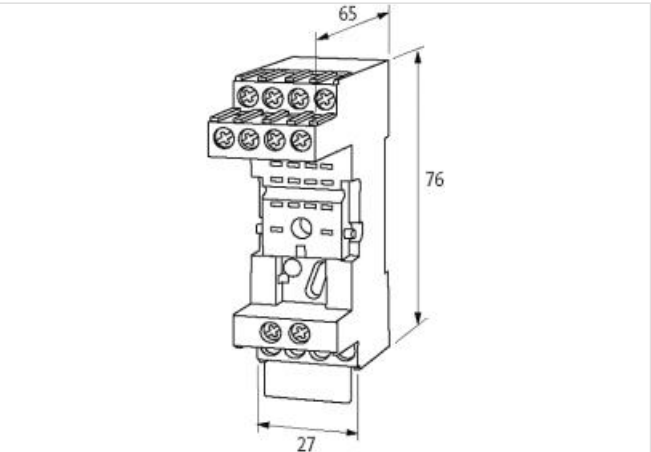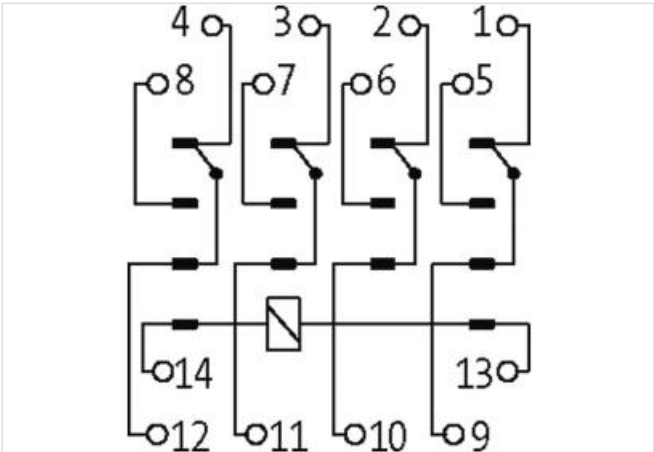

Product may differ from Image



Commercial data	
ECLASS-6.0	27371603
ECLASS-7.0	27371603
ECLASS-8.0	27371603
ECLASS-9.0	27371603
ETIM-5.0	EC001437
customs tariff number	85366990

GTIN	4048879025935
------	---------------

Packaging unit	1
----------------	---

**Electrical data | Output**

Switching voltage AC max.	250 V
---------------------------	-------

Switching voltage DC max.	110 V
---------------------------	-------

Switching current max.	5 A
------------------------	-----

**Installation | Connection**

Connection	Spring clamp terminals FK
------------	---------------------------

**Device protection | Electrical**

Degree of protection (EN IEC 60529)	IP40
-------------------------------------	------

**Mechanical data | Mounting data**

Mounting method	geschnappt
-----------------	------------

Suitable for mounting type	mounting rail, (EN 60715)
----------------------------	---------------------------

Height	76,5 mm
--------	---------

Width	27 mm
-------	-------

Depth	65 mm
-------	-------