

## EUROCARD HOLDER

SKP 32/1 F, 250V/4A, row b,z

Screw terminals

32-pole F (EN 60603)

Row b, z

250 V AC



With the vertical snap adapter SASA 135 Art.-No. 63900 the holder can be mounted at right-angles on the rail.

The D2 size is for a card without a front plate.

To insert the card first press down the 2 yellow buttons. Then slide the Eurocard into the guide slots pushing until fully engaged. The card is now locked into position. It can be removed by pressing down on the 2 yellow buttons.

### [Link to Product](#)

#### Illustration

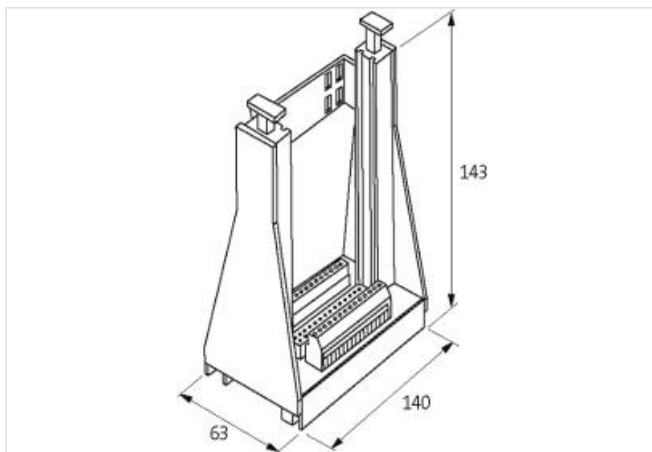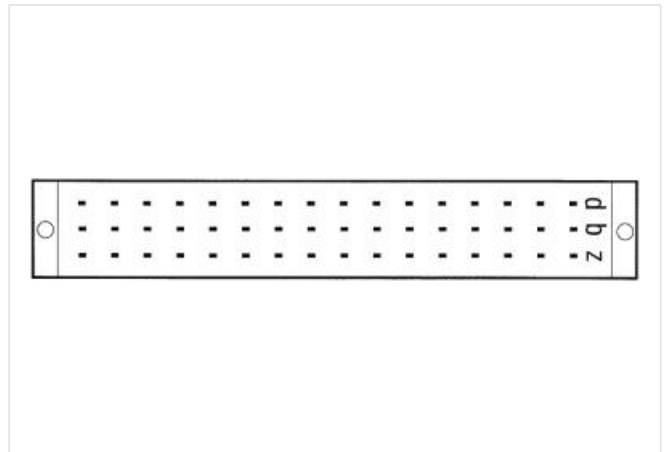

Product may differ from Image



#### Commercial data

ECLASS-6.0	27260710
ECLASS-6.1	27260704

ECLASS-7.0	27440402
ECLASS-8.0	27440402
ECLASS-9.0	27440402
ECLASS-10.1	27440402
ECLASS-11.1	27460201
ECLASS-12.0	27460201
ETIM-5.0	EC002780
customs tariff number	85366990
GTIN	4048879042192
Packaging unit	1

**Electrical data | Supply**

Operating voltage AC	250 V
Operating current max.	4 A

**Installation**

Connection cross-section solid max.	4 mm <sup>2</sup>
-------------------------------------	-------------------

**Installation | Pin assignment**

No. of poles	32
--------------	----

**Device protection | Electrical**

Overvoltage category (EN 60664-1)	I
-----------------------------------	---

**Device protection | Media**

Flame resistance	flame retardant
------------------	-----------------

**Mechanical data**

Type of socket connector	F (EN 60603)
--------------------------	--------------

**Mechanical data | Material data**

Material housing	Plastic
------------------	---------

**Mechanical data | Mounting data**

Mounting method	screwed, geschnappt
Suitable for mounting type	mounting rail, (EN 60715)