



**ASSEMBLY MODULE MKS - M 4**

Mounting rail / screw-type terminal

4 pairs of solder pins  
screw terminals connected to solder pin pairs

[Link to Product](#)

Illustration

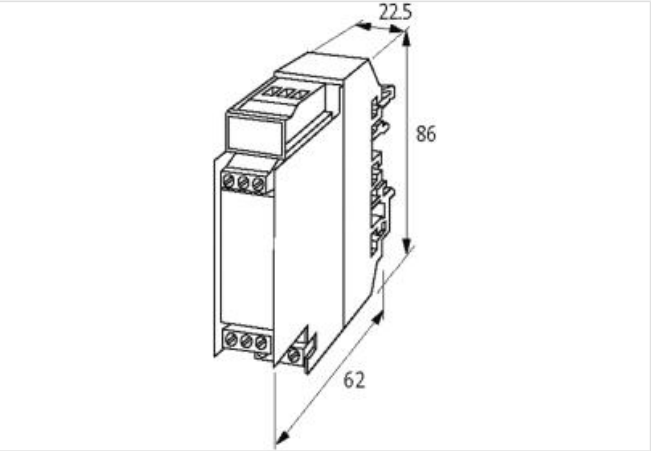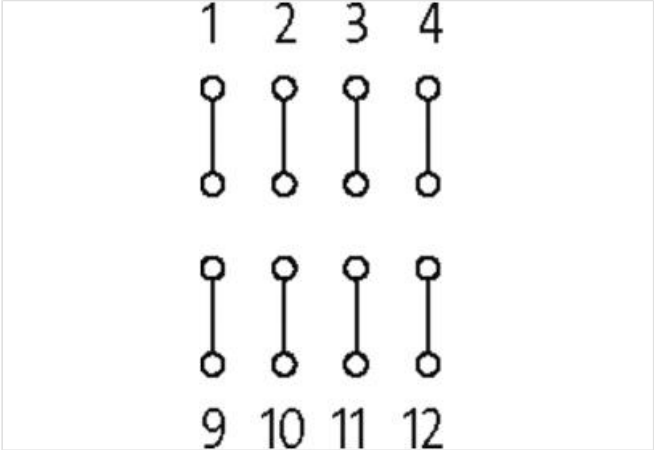

Product may differ from Image



Commercial data	
ECLASS-6.0	27379201
ECLASS-6.1	27141149
ECLASS-7.0	27141149
ECLASS-8.0	27141149
ECLASS-9.0	27141149
ECLASS-10.1	27141149
ECLASS-11.1	27141149
ECLASS-12.0	27141149

ETIM-5.0	EC002780
customs tariff number	85369010
GTIN	4048879041812
Packaging unit	1
<b>Electrical data   Supply</b>	
Operating voltage AC max.	250 V
Operating voltage DC max.	250 V
Operating current max.	2,5 A
<b>Device protection   Media</b>	
Flame resistance	flame retardant
<b>Mechanical data   Material data</b>	
Housing properties	removable cover
Material housing	Plastic
<b>Mechanical data   Mounting data</b>	
Distance of solder pins	30 mm
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, G32, (EN 60715)
Height	68 mm
Width	22,5 mm
Depth	65 mm
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
<b>Connection type 1</b>	
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	8