

HYBRID FIELD-BUS COUPLERS

MHA-BBE-E - 2 x M12


M12, M12 (female/female) B-coded; RS485 (SUB-D9)

Link to Product

Illustration



Product may differ from Image

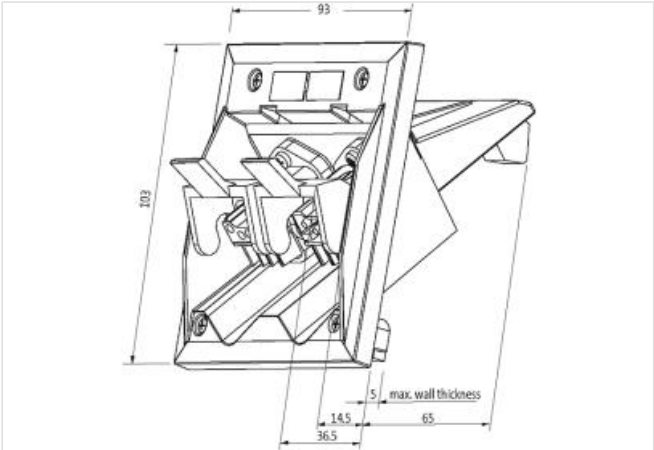

Commercial data	
ECLASS-6.0	27189217
ECLASS-7.0	27189217
ECLASS-8.0	27189217
ECLASS-9.0	27189217
ETIM-5.0	EC002641
customs tariff number	85371098
GTIN	4048879041478
Packaging unit	1
Electrical data   Supply	
Operating voltage DC	24 V
Industrial communication	
Data transmission rate max.	12 MBit/s
Installation	
Connection cross-section solid max.	0,25 mm²
Connection cross-section stranded/fine-stranded max.	2,5 mm²
Installation   Connection	
Connection	Spring clamp plug-in terminals
Device protection	
Shielded	no
Device protection   Media	
Flame resistance	flame retardant

**Mechanical data | Material data**

Color housing	black
Material housing	Plastic

**Mechanical data | Mounting data**

Height cutout	90 mm
Width cutout	80 mm
Height	103 mm
Width	93 mm
Depth	65 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-25 °C
Operating temperature max.	50 °C