

MSVD POWER SOCKET NEMA (GFCI)

Mounting rail

USA (2× NEMA-GFCI 5-15)  
(Ground Fault Circuit Interrupter)  
Screw terminals


Each socket can be loaded with 20 A, however, the total load of both sockets must be below 30 A.

Link to Product

Illustration



Product may differ from Image

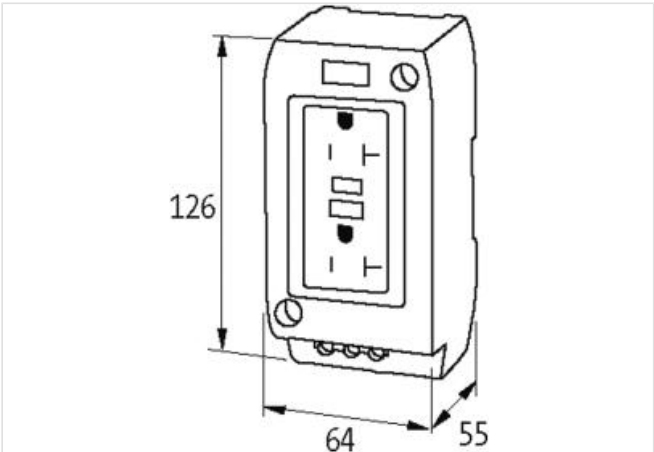

Commercial data	
ECLASS-6.0	27189217
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-8.0	27142305
ECLASS-9.0	27142305
ECLASS-10.1	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305
ETIM-5.0	EC000020
customs tariff number	85366990
GTIN	4048879041393
Packaging unit	1
Electrical data	
Fault current min.	4 mA
Fault current max.	6 mA
Electrical data   Supply	
Operating voltage AC	125 V
Operating current max.	15 A
Installation	
Connection cross section max.	6 mm²

**Installation | Connection**

Connection	Screw terminals SK
------------	--------------------

**Mechanical data | Mounting data**

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	126 mm
Width	64 mm
Depth	55 mm