



LED-INDICATOR YELLOW

LED 3mm - 24V DC - IP40

(yellow)
24 V DC

[Link to Product](#)

Illustration

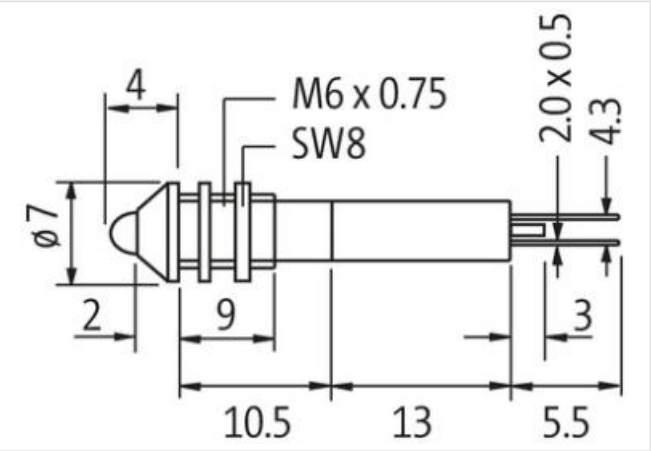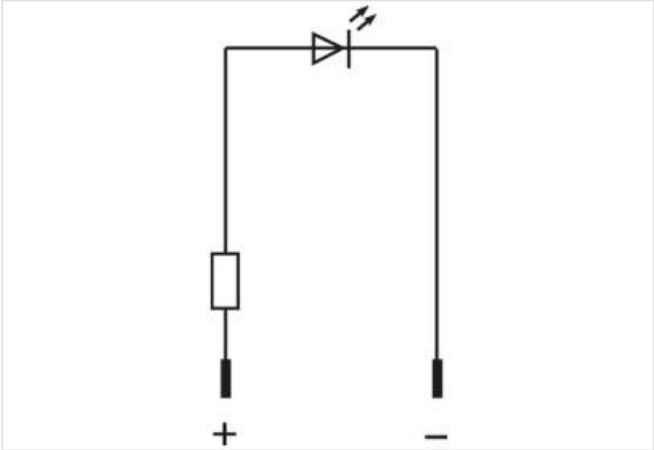

Product may differ from Image

Commercial data	
ECLASS-6.0	27261590
ECLASS-6.1	27261501
ECLASS-7.0	27261501
ECLASS-8.0	27261501
ECLASS-9.0	27261501
ECLASS-10.1	27261501
ECLASS-11.1	27261501
ECLASS-12.0	27261501
ETIM-5.0	EC000272
customs tariff number	85318070
GTIN	4048879041171
Packaging unit	10

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	20,4 V
Operating voltage DC max.	26,4 V
Current consumption max.	18 mA

Installation | Connection

Connection information	Faston 2.0×0.5 mm
------------------------	-------------------

Mechanical data | Material data

Coating housing	chrome-plated
Material housing	Brass

Mechanical data | Mounting data

Height	7 mm
Width	7 mm
Depth	33 mm

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	70 °C