



LED-INDICATOR YELLOW

LED 5mm - 24V DC - IP40

(yellow)  
24 V DC

Link to Product

Illustration

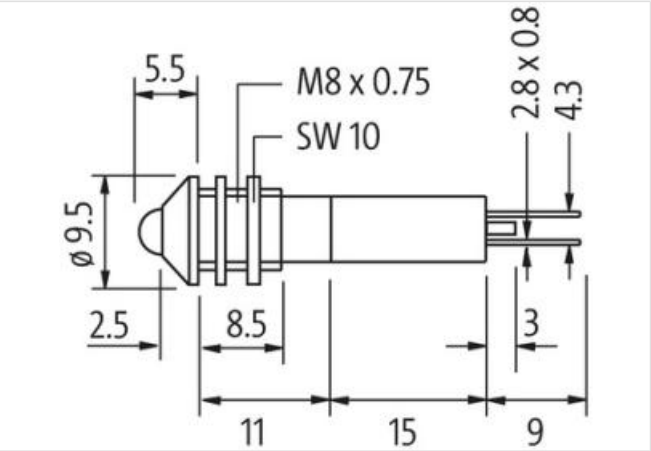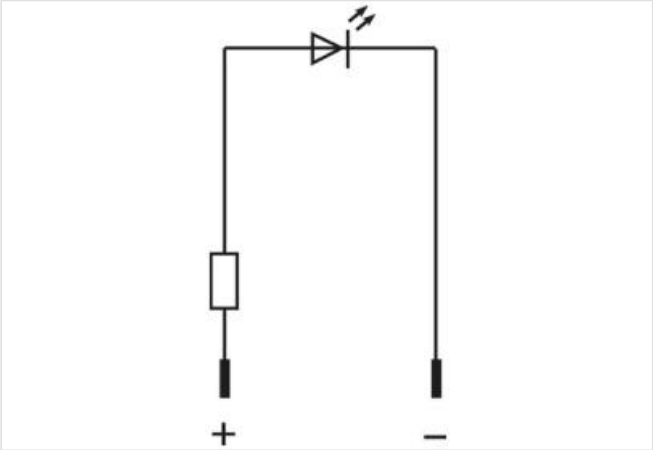

Product may differ from Image

Commercial data	
ECLASS-6.0	27261590
ECLASS-6.1	27261501
ECLASS-7.0	27261501
ECLASS-8.0	27261501
ECLASS-9.0	27261501
ECLASS-10.1	27261501
ECLASS-11.1	27261501
ECLASS-12.0	27261501
ETIM-5.0	EC000272
customs tariff number	85318070
GTIN	4048879041164
Packaging unit	10

**Electrical data | Supply**

Operating voltage DC	24 V
Operating voltage DC min.	20,4 V
Operating voltage DC max.	26,4 V
Current consumption max.	18 mA

**Installation | Connection**

Connection information	Faston 2.8×0.8 mm
------------------------	-------------------

**Mechanical data | Material data**

Coating housing	chrome-plated
Material housing	Brass

**Mechanical data | Mounting data**

Height	9,5 mm
Width	9,5 mm
Depth	77,5 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-40 °C
Operating temperature max.	70 °C