



LED-INDICATOR BLUE

LED 5mm - 24V DC - IP40

(blue)
24 V DC

Link to Product

Illustration

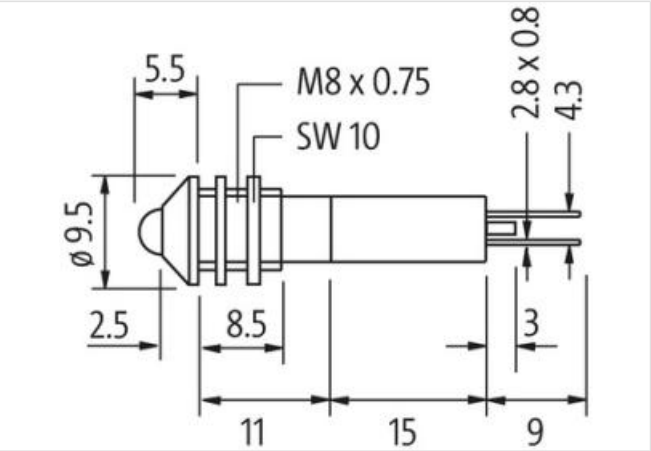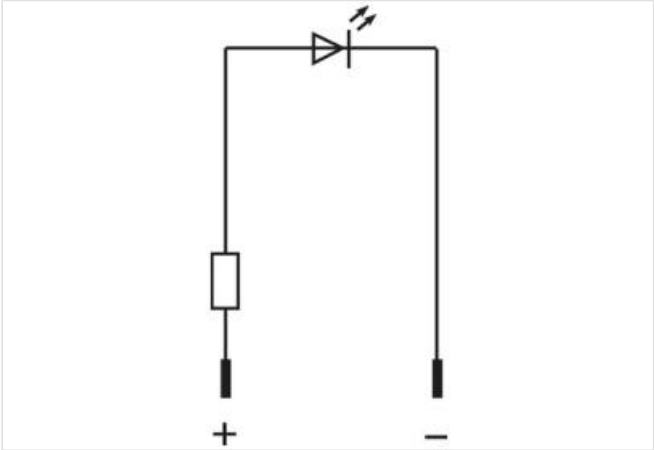

Product may differ from Image

Commercial data	
ECLASS-6.0	27261590
ECLASS-6.1	27261501
ECLASS-7.0	27261501
ECLASS-8.0	27261501
ECLASS-9.0	27261501
ECLASS-10.1	27261501
ECLASS-11.1	27261501
ECLASS-12.0	27261501
ETIM-5.0	EC000272
customs tariff number	85318070
GTIN	4048879041102
Packaging unit	10

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	20,4 V
Operating voltage DC max.	26,4 V
Current consumption max.	0,9 mA

Installation | Connection

Connection information	Faston 2.8×0.8 mm
------------------------	-------------------

Mechanical data | Material data

Coating housing	chrome-plated
Material housing	Brass

Mechanical data | Mounting data

Height	9,5 mm
Width	9,5 mm
Depth	77,5 mm

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	70 °C