



LED-INDICATOR BLUE

LED 5mm - 24V AC/DC - 15mA - IP40

(blue)  
24 V AC/DC  
Protection IP40

[Link to Product](#)

Illustration

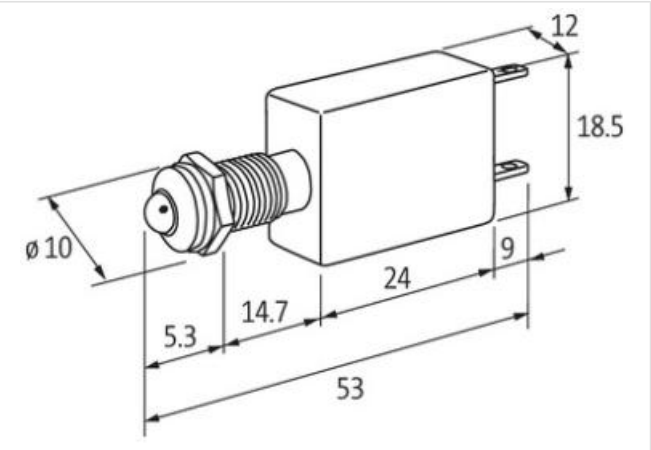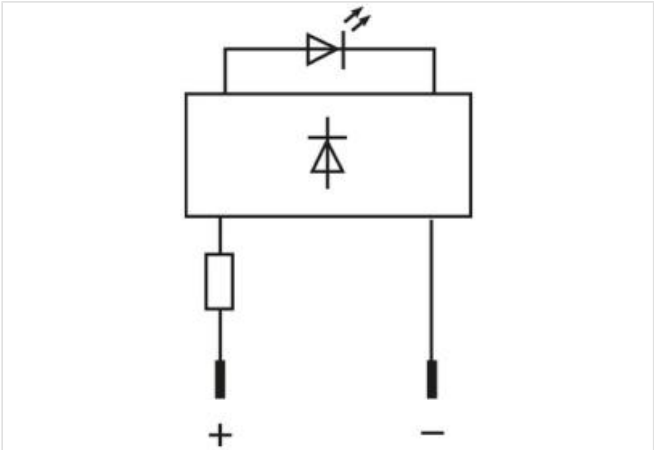

Product may differ from Image

Commercial data	
ECLASS-6.0	27261590
ECLASS-6.1	27261501
ECLASS-7.0	27261501
ECLASS-8.0	27261501
ECLASS-9.0	27261501
ECLASS-10.1	27261501
ECLASS-11.1	27261501
ECLASS-12.0	27261501
ETIM-5.0	EC000272
customs tariff number	85318070
GTIN	4048879040969

Packaging unit 10

**Electrical data | Supply**

Operating voltage AC	24 V
Operating voltage AC min.	20,4 V
Operating voltage AC max.	26,4 V
Operating voltage DC	24 V
Operating voltage DC min.	20,4 V
Operating voltage DC max.	26,4 V
Current consumption min.	13 mA
Current consumption max.	17 mA

**Installation | Connection**

Connection information Faston 2.8x0.8 mm

**Device protection | Electrical**

Degree of protection (EN IEC 60529) IP40

**Mechanical data**

Diameter LED 5 mm

**Mechanical data | Material data**

Color housing gray  
Material housing PVC

**Mechanical data | Mounting data**

Diameter front panel drilling 8 mm  
Height 18,5 mm  
Width 12 mm  
Depth 53 mm

**Environmental characteristics | Climatic**

Operating temperature min. -40 °C  
Operating temperature max. 70 °C