



LED-display 230V AC blue

Product discontinued, no alternative

(blue)  
230 V AC/DC  
Protection IP40

Link to Product

Illustration

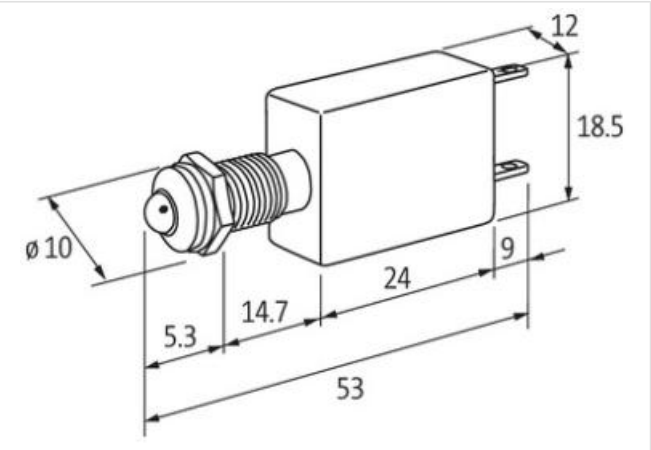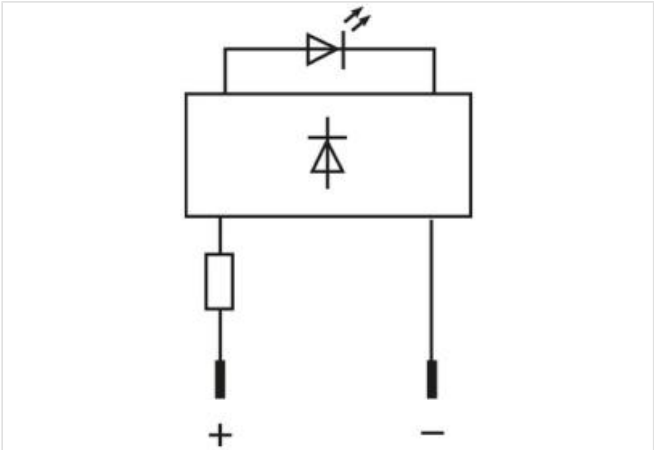

Product may differ from Image

Commercial data	
ECLASS-6.0	27261590
ECLASS-7.0	27261590
ECLASS-8.0	27261590
ECLASS-9.0	27261590
ETIM-5.0	EC000272
customs tariff number	85318070
GTIN	4048879040945
Packaging unit	10
Electrical data   Supply	
Operating voltage AC	230 V
Operating voltage AC min.	207 V

Operating voltage AC max.	253 V
Current consumption min.	4,5 mA
Current consumption max.	5,5 mA
<b>Installation   Connection</b>	
Connection information	Faston 2.8x0.8 mm
<b>Device protection   Electrical</b>	
Degree of protection (EN IEC 60529)	IP40
<b>Mechanical data</b>	
Diameter LED	5 mm
<b>Mechanical data   Material data</b>	
Color housing	gray
Material housing	PVC
<b>Mechanical data   Mounting data</b>	
Diameter front panel drilling	8 mm
Height	18,5 mm
Width	12 mm
Depth	53 mm
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-40 °C
Operating temperature max.	70 °C