



LED-display 24V DC lamp-test green

Product discontinued, no alternative

(green)  
24 V DC  
Protection IP40  
with lamp test input

Link to Product

Illustration

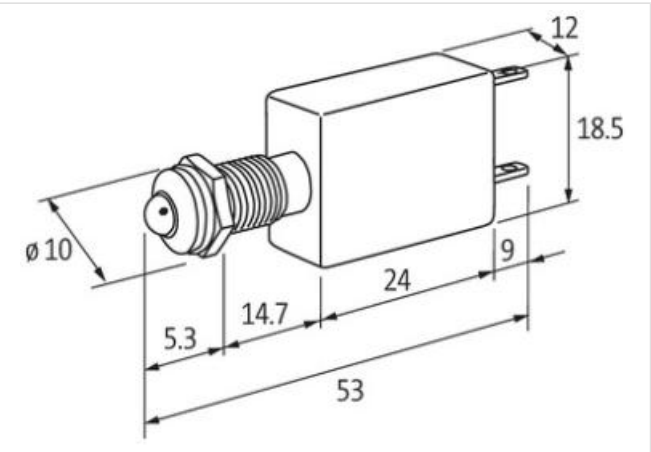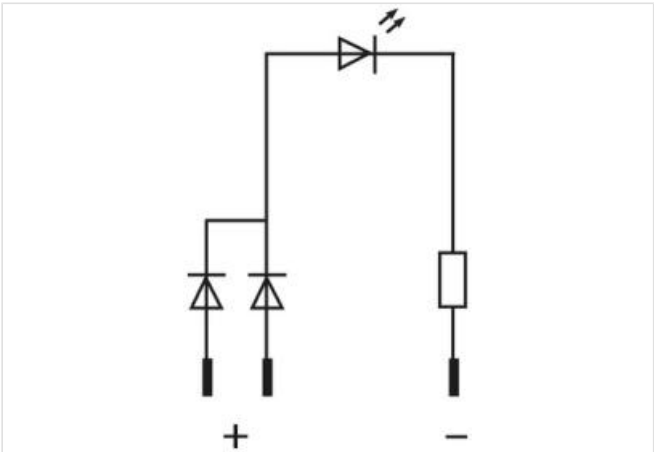

Product may differ from Image

Commercial data	
ECLASS-6.0	27261590
ECLASS-7.0	27261590
ECLASS-8.0	27261590
ECLASS-9.0	27261590
ETIM-5.0	EC000272
customs tariff number	85318070
GTIN	4048879040884
Packaging unit	10
Electrical data   Supply	
Operating voltage AC	24 V

Operating voltage AC min.	20,4 V
Operating voltage AC max.	26,4 V
Operating voltage DC	24 V
Operating voltage DC min.	20,4 V
Operating voltage DC max.	26,4 V
Current consumption min.	13 mA
Current consumption max.	17 mA

**Installation | Connection**

Connection information	Faston 2.8×0.8 mm
------------------------	-------------------

**Device protection | Electrical**

Degree of protection (EN IEC 60529)	IP40
-------------------------------------	------

**Mechanical data**

Diameter LED	5 mm
--------------	------

**Mechanical data | Material data**

Color housing	gray
Material housing	PVC

**Mechanical data | Mounting data**

Diameter front panel drilling	8 mm
Height	18,5 mm
Width	12 mm
Depth	53 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-40 °C
Operating temperature max.	70 °C