



LED-display red 110V AC/DC IP67

Product discontinued, no alternative

(red)  
110 V AC/DC  
Protection IP67  
with touch protection

Link to Product

Illustration

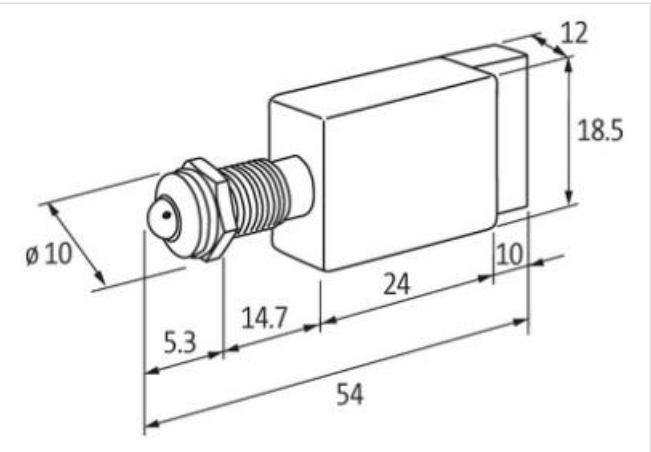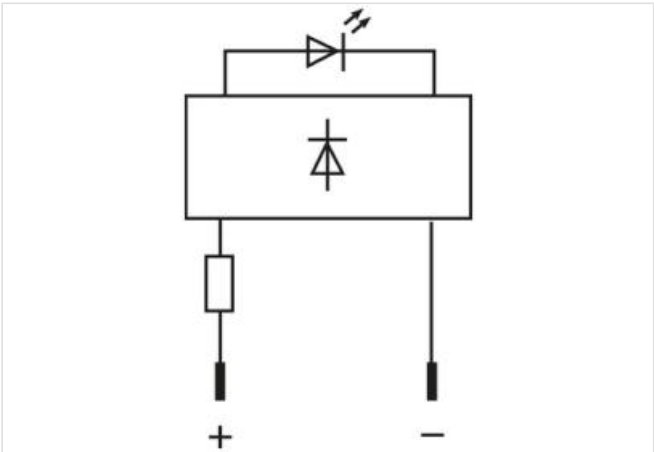

Product may differ from Image

Commercial data

ECLASS-6.0	27261590
ECLASS-7.0	27261590
ECLASS-8.0	27261590
ECLASS-9.0	27261590
ETIM-5.0	EC000272
customs tariff number	85318070
GTIN	4048879040761
Packaging unit	10

Electrical data | Supply

Operating voltage AC	110 V
----------------------	-------

Operating voltage AC min.	95 V
Operating voltage AC max.	121 V
Operating voltage DC	110 V
Operating voltage DC min.	95 V
Operating voltage DC max.	121 V
Current consumption min.	4,5 mA
Current consumption max.	5,5 mA

**Installation | Connection**

Connection information	Faston 2.8×0.8 mm
------------------------	-------------------

**Device protection | Electrical**

Degree of protection (EN IEC 60529)	IP67
-------------------------------------	------

**Mechanical data**

Diameter LED	5 mm
--------------	------

**Mechanical data | Material data**

Color housing	gray
Material housing	PVC

**Mechanical data | Mounting data**

Diameter front panel drilling	8 mm
Height	18,5 mm
Width	12 mm
Depth	54 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-40 °C
Operating temperature max.	70 °C