



LED-INDICATOR RED/GREEN

LED 5mm - 24V DC - 15mA - IP67

(red/green)
24 V DC
Protection IP67
with touch protection

[Link to Product](#)

Illustration

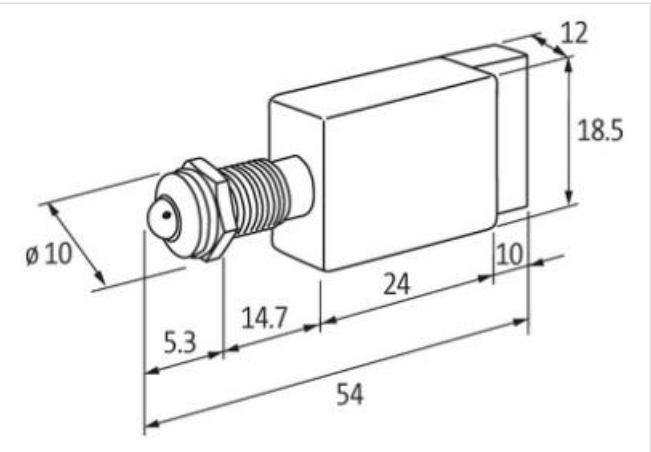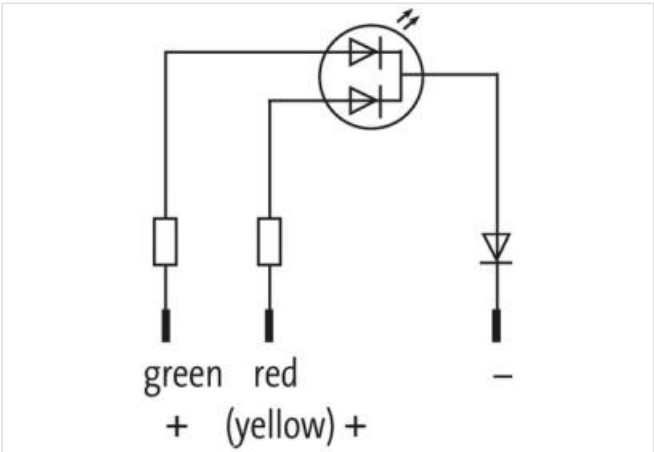

Product may differ from Image

Commercial data	
ECLASS-6.0	27261590
ECLASS-6.1	27261501
ECLASS-7.0	27261501
ECLASS-8.0	27261501
ECLASS-9.0	27261501
ECLASS-10.1	27261501
ECLASS-11.1	27261501
ECLASS-12.0	27261501
ETIM-5.0	EC000272
customs tariff number	85318070
GTIN	4048879040556

Packaging unit 10

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	20,4 V
Operating voltage DC max.	26,4 V
Current consumption min.	13 mA
Current consumption max.	17 mA

Installation | Connection

Connection information Faston 2.8x0.8 mm

Device protection | Electrical

Degree of protection (EN IEC 60529) IP67

Mechanical data

Diameter LED 5 mm

Mechanical data | Material data

Color housing	gray
Material housing	PVC

Mechanical data | Mounting data

Diameter front panel drilling	8 mm
Height	18,5 mm
Width	12 mm
Depth	54 mm

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	70 °C