



MB CAP ULTRA BUFFER MODULE

IN: 24VDC OUT: 24VDC/40A for max. 1A/170S

INPUT: 24 V DC (SELV/PELV)  
OUTPUT: max. 40 A  
3.6 s (40 A); 170 s (1 A)

Link to Product

Illustration

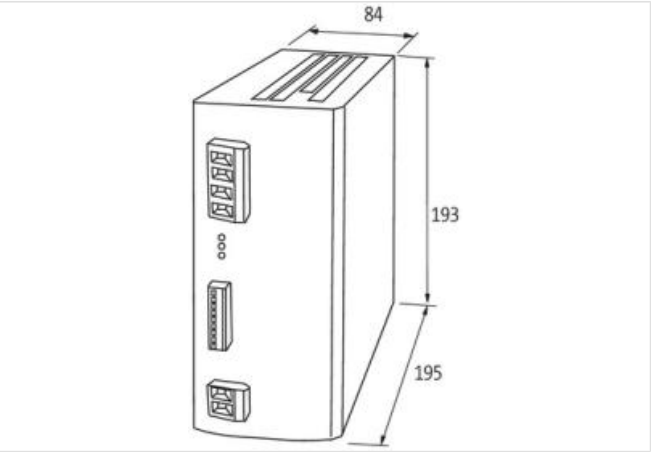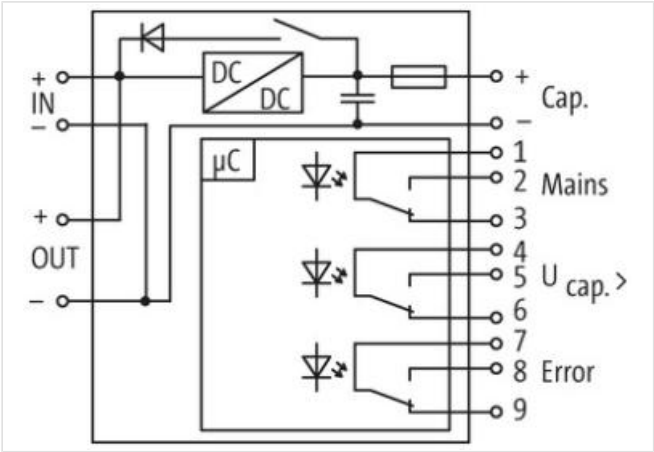

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27049190 |
| ECLASS-6.1      | 27049002 |
| ECLASS-7.0      | 27049002 |
| ECLASS-8.0      | 27049002 |
| ECLASS-9.0      | 27040705 |
| ECLASS-10.1     | 27040705 |

|                       |               |
|-----------------------|---------------|
| ECLASS-11.1           | 27040705      |
| ECLASS-12.0           | 27040705      |
| ETIM-5.0              | EC002584      |
| customs tariff number | 85322900      |
| GTIN                  | 4048879404990 |
| Packaging unit        | 1             |

**Electrical data | Input**

|                       |        |
|-----------------------|--------|
| Input voltage DC min. | 21,6 V |
| Input voltage DC max. | 26,4 V |
| Current input AC      | 40 A   |
| Max. inrush current   | 36,5 A |
| Charging time min.    | 140 s  |
| Charging time max.    | 300 s  |
| Efficiency            | 90 %   |

**Electrical data | Output**

|                           |        |
|---------------------------|--------|
| Output voltage DC min.    | 19 V   |
| Output voltage DC max.    | 25,5 V |
| Output voltage adjustable | yes    |
| Output current max.       | 40 A   |

**Mechanical data | Mounting data**

|                            |                                          |
|----------------------------|------------------------------------------|
| Mounting method            | geschnappt                               |
| Suitable for mounting type | Tragschiene TH35-7.5/TH35-15, (EN 60715) |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 60 °C  |
| Storage temperature min.   | -20 °C |
| Storage temperature max.   | 60 °C  |