



NG 2 RECTIFIER UNIT 1-PHASE

IN: 41VAC OUT: 24V/2,6A

Rectifiers, single phase  
INPUT: max. 41 V AC  
Output rating: 62 W  
Current: max. 2.6 A

[Link to Product](#)

Illustration

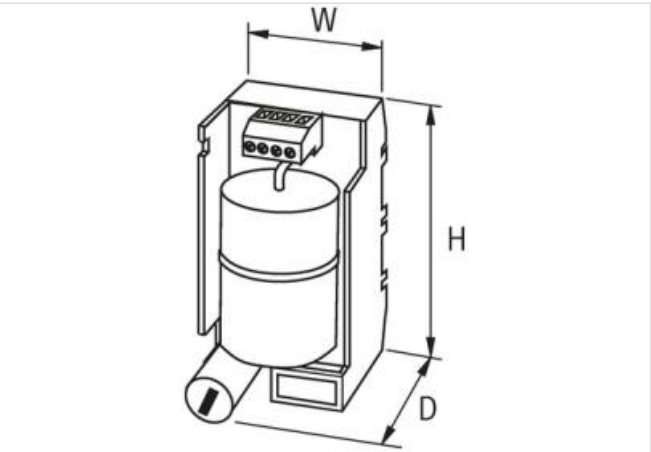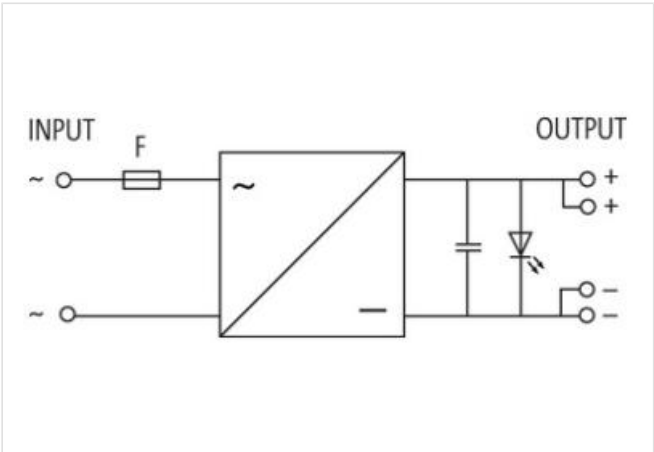

Product may differ from Image



Commercial data	
ECLASS-6.0	27049002
ECLASS-6.1	27040390
ECLASS-7.0	27040390
ECLASS-8.0	27040390
ECLASS-9.0	27040390
ECLASS-10.1	27040390

ECLASS-11.1	27040390
ECLASS-12.0	27040390
ETIM-5.0	EC002540
customs tariff number	85044083
GTIN	4048879079495
Packaging unit	5

**Electrical data | Supply**

Power frequency	45 ... 65 Hz
-----------------	--------------

**Electrical data | Input**

Fuse protection primary side internal	3,15 A
Characteristic back-up fuse	Inertia
Input voltage AC min.	5 V
Input voltage AC max.	44 V
Input current DC max.	2,6 A

**Electrical data | Output**

Output suppression	LED, screened with electrolytic capacitor
Output voltage DC max.	60 V
Output voltage adjustable	no
Output current max.	2,6 A
Ripple max.	5 %

**Mechanical data | Mounting data**

Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Height	86 mm
Width	45 mm
Depth	92 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Derating from	30 °C

**Connection type 2**

Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	2
PIN 1	U E AC
PIN 2	U E AC
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	4
PIN 1	U A -
PIN 2	U A -
PIN 3	U A +
PIN 4	U A +