



MST 1-PHASE CONTROL AND ISOLATION TRANSFORMER

P: 630VA IN:230/400VAC+/-15VAC OUT: 2x115VAC

Single-phase - Control and Isolation Transformers  
630 VA  
Isolation class T 40/B  
Condensation not permitted

[Link to Product](#)

Illustration

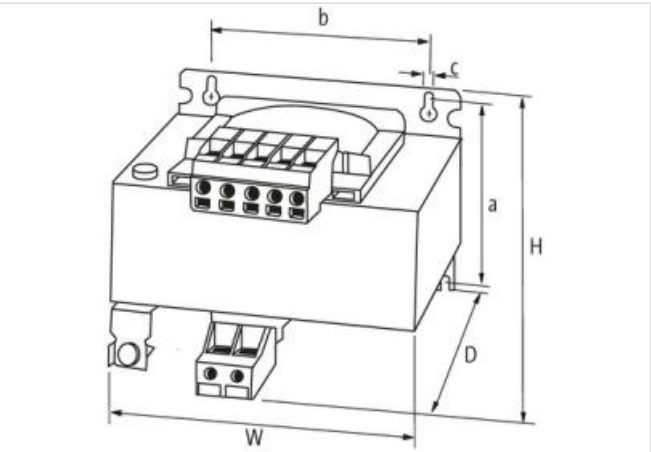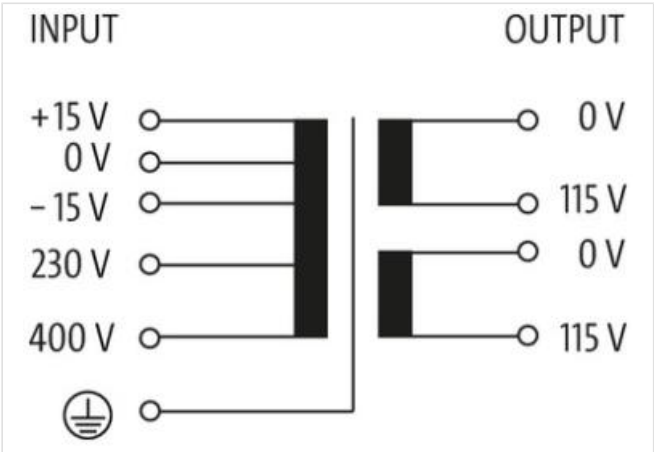

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27031302 |
| ECLASS-6.1      | 27031302 |
| ECLASS-7.0      | 27031302 |
| ECLASS-8.0      | 27031302 |
| ECLASS-9.0      | 27031302 |
| ECLASS-10.1     | 27031302 |

|                       |               |
|-----------------------|---------------|
| ECLASS-11.1           | 27031302      |
| ECLASS-12.0           | 27031302      |
| ETIM-5.0              | EC002486      |
| customs tariff number | 85043180      |
| GTIN                  | 4048879366830 |
| Packaging unit        | 1             |

**Electrical data | Supply**

|                 |              |
|-----------------|--------------|
| Power frequency | 50 ... 60 Hz |
|-----------------|--------------|

**Electrical data | Input**

|                                          |         |
|------------------------------------------|---------|
| Input voltage 1 AC                       | 230 V   |
| Input voltage 1 AC min.                  | 195,5 V |
| Input voltage 1 AC max.                  | 264,5 V |
| Input voltage 2 AC                       | 400 V   |
| Input voltage 2 AC min.                  | 340 V   |
| Input voltage 2 AC max.                  | 460 V   |
| Input current at input voltage 1 AC      | 3 A     |
| Input current at input voltage 2 AC      | 1,7 A   |
| Inrush current at input voltage 1        | 56 A    |
| Inrush current at input voltage 2        | 26 A    |
| Short-circuit current at input voltage 1 | 72 A    |
| Short-circuit current at input voltage 2 | 39 A    |

**Electrical data | Output**

|                           |                                  |
|---------------------------|----------------------------------|
| Output voltage            | 1 × 230 / 1 × 115 / 2 × 115 V AC |
| Output voltage AC 1       | 230 V                            |
| Output voltage AC 2       | 115 V                            |
| Output voltage adjustable | yes                              |
| Power rating AC max.      | 630 VA                           |

**Device protection | Electrical**

|                                        |        |
|----------------------------------------|--------|
| Insulation test voltage input - output | 5,8 kV |
|----------------------------------------|--------|

**Mechanical data | Mounting data**

|                            |                        |
|----------------------------|------------------------|
| Suitable for mounting type | Schlüssellochabhängung |
| Mounting dimension a       | 90,6 mm                |
| Mounting dimension b       | 122 mm                 |
| Mounting dimension c       | 7 mm                   |
| Height                     | 112,5 mm               |
| Width                      | 150 mm                 |
| Depth                      | 146 mm                 |
| Diameter bore              | 7 mm                   |
| Length bore                | 11 mm                  |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 40 °C  |

**Conformity**

|                  |                                               |
|------------------|-----------------------------------------------|
| Product standard | EN 61558-1, EN 61558-2-4, EN 62041 category 0 |
|------------------|-----------------------------------------------|

**Connection type 3**

|                          |                    |
|--------------------------|--------------------|
| Connection type 1        | Input              |
| Connection type 2        | Output             |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| No. of poles             | 5                  |

|                          |                    |
|--------------------------|--------------------|
| PIN 1                    | + 15 V             |
| PIN 3                    | - 15 V             |
| PIN 4                    | 230 V              |
| PIN 5                    | 400 V              |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| No. of poles             | 6                  |
| PIN 1                    | 1                  |
| PIN 2                    | 2                  |
| PIN 3                    | 3                  |
| PIN 4                    | 4                  |
| PIN 5                    | 5                  |
| PIN 6                    | 6                  |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| Color contact carrier    | metallic           |
| No. of poles             | 1                  |
| PIN 1                    | PE                 |