



MOTOR SUPPRESSION SHIELDING PLUGGABLE 10M PUR

(black-halogenfree)

3× 575 V AC  
VDR/star  
10.0 m  
PUR cable black, 4× 1.5 mm², numbered wires, halogen-free

[Link to Product](#)

Illustration

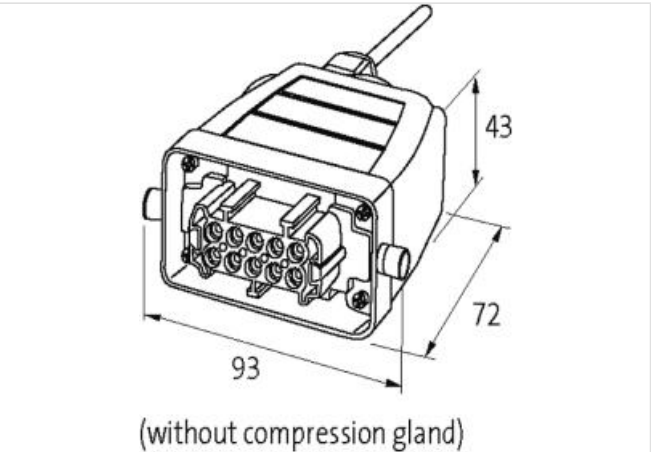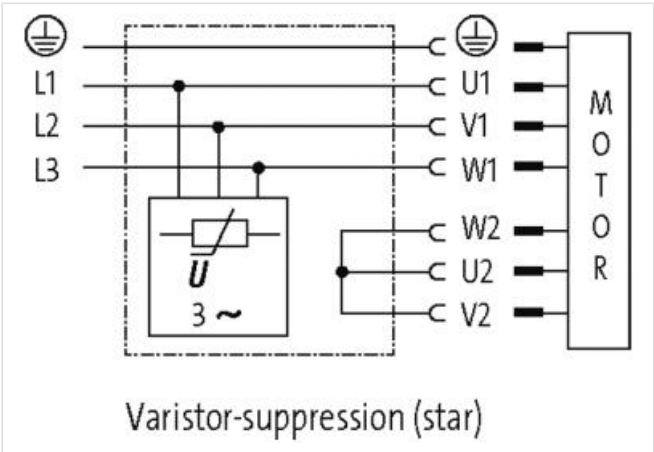

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
customs tariff number	85363010
GTIN	4048879015141
Packaging unit	1
<b>Electrical data   Supply</b>	
Power frequency	10 ... 400 Hz
<b>Electrical data   Input</b>	
Input voltage AC min.	400 V
Input voltage AC max.	575 V
<b>Installation   Connection</b>	
Gender	female
<b>Installation   Pin assignment</b>	
No. of poles	10 + PE
<b>Mechanical data   Material data</b>	
Coating housing	powder-coated
Material housing	Aluminum die casting
<b>Mechanical data   Mounting data</b>	
Height	72 mm
Width	93 mm
Depth	43 mm
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C