

MSVD POWER SOCKET NEMA WITH LED

Mounting rail


USA (NEMA 5-15)
Connection turned
Screw terminals
LED (yellow)

[Link to Product](#)

Illustration



Product may differ from Image

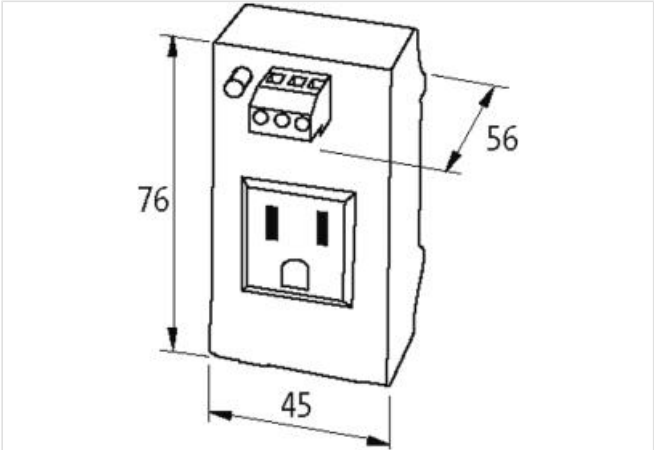

Commercial data	
ECLASS-6.0	27189217
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-8.0	27142305
ECLASS-9.0	27142305
ECLASS-10.1	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305
ETIM-5.0	EC000020
customs tariff number	85366990
GTIN	4048879039680
Packaging unit	1
Electrical data Supply	
Operating voltage AC	127 V
Operating current	15 A
Installation	
Connection cross section max.	2,5 mm²
AWG number	14
Installation Connection	
Connection	Screw terminals SK

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	75 mm
Width	45 mm
Depth	56 mm