



VALVE PLUG SUPPRESSOR FORM A - 18MM

With LED, 24VAC/DC/50VA/W

24 V AC/DC
LED
Remove plug gasket when fitting adapter. Other LED colors on request.

Link to Product

Illustration

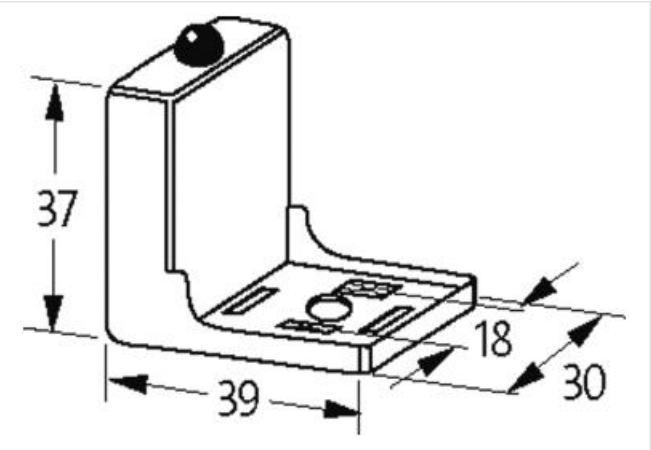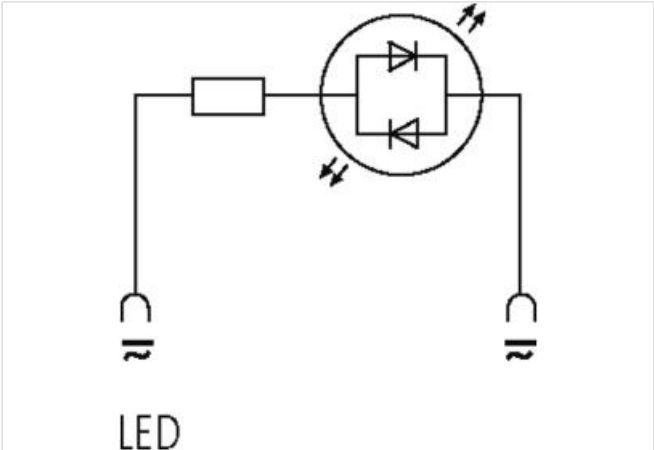

Product may differ from Image



| Commercial data | |
|-----------------|----------|
| ECLASS-6.0 | 27371013 |
| ECLASS-6.1 | 27371013 |
| ECLASS-7.0 | 27371013 |
| ECLASS-8.0 | 27371013 |
| ECLASS-9.0 | 27371013 |
| ECLASS-10.1 | 27371013 |

| | |
|---|-----------------|
| ECLASS-11.1 | 27371013 |
| ECLASS-12.0 | 27371013 |
| ETIM-5.0 | EC000197 |
| customs tariff number | 85363010 |
| GTIN | 4048879012300 |
| Packaging unit | 1 |
| Electrical data | |
| Holding power max. | 50 W |
| Electrical data Input | |
| Input voltage AC min. | 12 V |
| Input voltage AC max. | 24 V |
| Input voltage DC min. | 12 V |
| Input voltage DC max. | 24 V |
| Diagnostics | |
| Status indication LED | yellow |
| Device protection Media | |
| Flame resistance | flame retardant |
| Mechanical data Material data | |
| Coating contact | silver-plated |
| Color housing | black |
| Material housing | PA |
| Material contact | Bronze |
| Mechanical data Mounting data | |
| Height | 37 mm |
| Width | 39 mm |
| Depth | 30 mm |
| Environmental characteristics Climatic | |
| Operating temperature min. | -20 °C |
| Operating temperature max. | 60 °C |
| Housing temperature max. (EN 61347-2-13) | 130 °C |