

**CAP FOR D-BOX M12 6-WAY 5-POLE**

Pot.-sep. 3m PUR/PVC-JB, 12x0,34+5x0,75

for 6-way distribution boxes, 5-pole

PUR/PVC

3.0 m

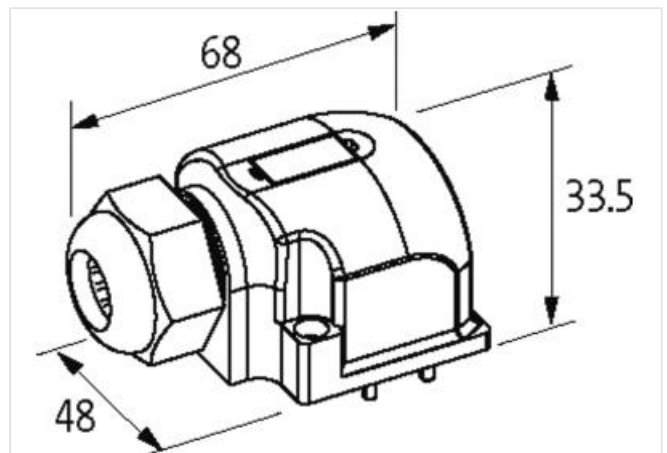
potentially separated

New Art.-No. 8000-86659-3920300

Plastic housings with good resistance against chemicals and oils.

**[Link to Product](#)****Illustration**

Product may differ from Image

**Commercial data**

ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440108
ECLASS-11.1	27440108
ECLASS-12.0	27440108
ETIM-5.0	EC002585
customs tariff number	85444290
GTIN	4048879058155
Packaging unit	1

**Electrical data | Supply**

Total current max.	8 A
--------------------	-----

**Mechanical data | Mounting data**

Height	33 mm
Width	48 mm
Depth	68 mm

**Connection type 2**

Family construction form	M12
Gender	female
Color contact carrier	black

Coding	A
No. of poles	5
PIN 1	+
PIN 2	NC S 2
PIN 3	-
PIN 4	NO S 1
PIN 5	PE
Connection type 1	X1-X8
Family construction form	free cable end
Color contact carrier	gray
No. of poles	17
Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	5
PIN 1	+
PIN 2	NC S 2
PIN 3	-
PIN 4	NO S 1
PIN 5	PE
Family construction form	free cable end
Color contact carrier	gray
No. of poles	17