

## CAP FOR D-BOX M12 6-WAY 5-POLE

Pot.-sep. 10m PUR/PVC-JB, 12x0,34+5x0,75

for 6-way distribution boxes, 5-pole

PUR/PVC

10.0 m

potentially separated

New Art.-No. 8000-86659-3921000


Plastic housings with good resistance against chemicals and oils.

### [Link to Product](#)

#### Illustration



Product may differ from Image

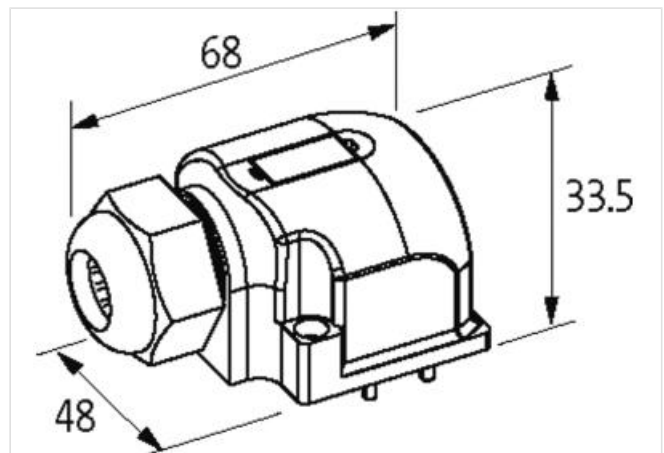

#### Commercial data

ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440108
ECLASS-11.1	27440108
ECLASS-12.0	27440108
ETIM-5.0	EC002585
customs tariff number	85444290
GTIN	4048879058131
Packaging unit	1

#### Electrical data | Supply

Total current max.	8 A
--------------------	-----

#### Mechanical data | Mounting data

Height	33 mm
Width	48 mm
Depth	68 mm

#### Connection type 2

Family construction form	M12
Gender	female
Color contact carrier	black

Coding	A
No. of poles	5
PIN 1	+
PIN 2	NC S 2
PIN 3	-
PIN 4	NO S 1
PIN 5	PE
Connection type 1	X1-X8
Family construction form	free cable end
Color contact carrier	gray
No. of poles	17
Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	5
PIN 1	+
PIN 2	NC S 2
PIN 3	-
PIN 4	NO S 1
PIN 5	PE
Family construction form	free cable end
Color contact carrier	gray
No. of poles	17