



MVP12, 6XM12, MOSA, PLUGGABLE CABLE

10.0m PUR-JB 12x0,34+5x0,75

6-way, 5-pole, MOSA
PUR/PVC (UL/CSA)
10.0 m
potentially separated
with LED for digital PNP-signals 24 V DC
quick connection elements included

Link to Product

Illustration

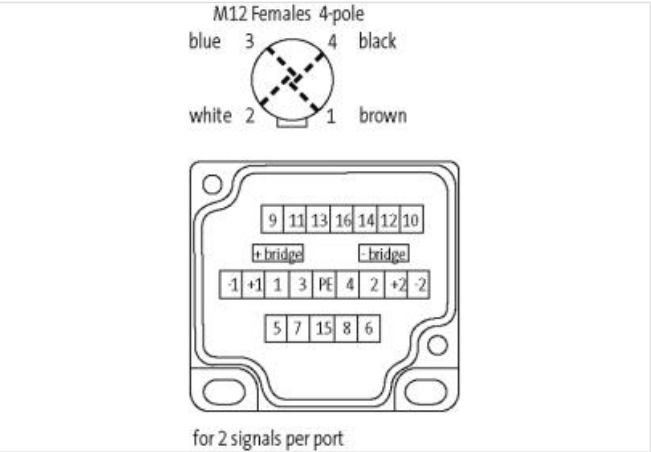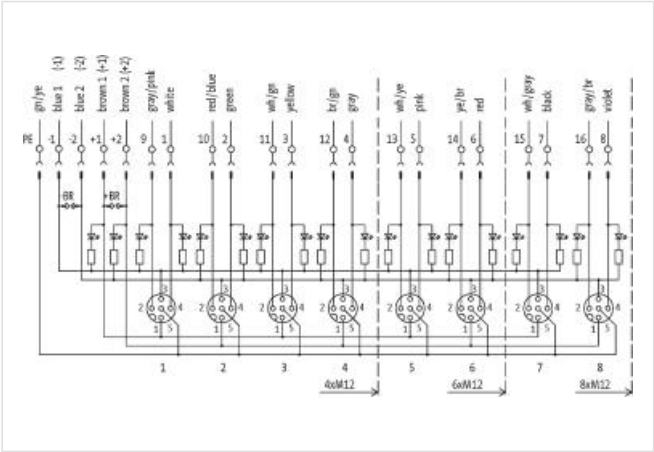

Product may differ from Image

Commercial data	
ECLASS-6.0	27279219
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440108
ECLASS-11.1	27440108
ECLASS-12.0	27440108

ETIM-5.0	EC002585
customs tariff number	85369010
GTIN	4048879057592
Packaging unit	1

Electrical data | Supply

Operating voltage DC	24 V
Current operating per contact max.	4 A
Total current at 1 time current feed-in max.	8 A
Total current at 2 times current feed-in max.	16 A

Industrial communication

Number of signals per port	2
----------------------------	---

Installation

Connection cross section min.	0,25 mm ²
Connection cross section max.	0,5 mm ²

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	screwed, mounted

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
------------------	---------

Mechanical data | Mounting data

Mounting method	Cap nut
Height	43 mm
Width	50,2 mm
Depth	122 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	80 °C