
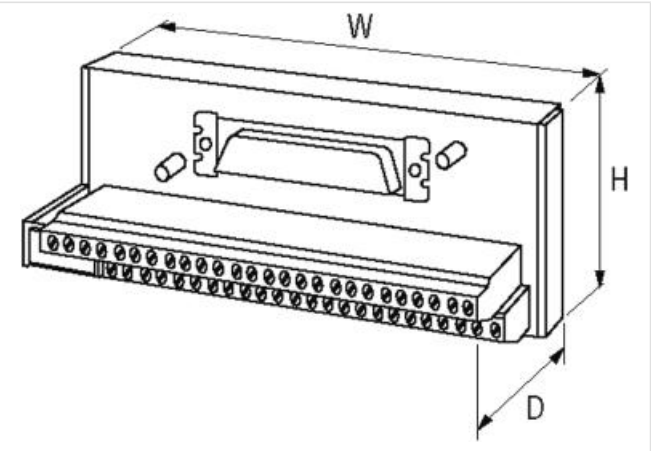


SV-SUB D 9BU.-KL FK

Female connector  
9-pole  
Spring clamp terminals

Link to Product

Illustration

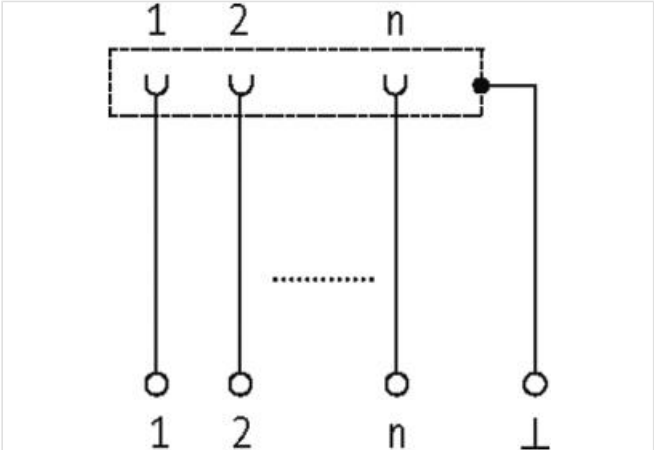

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27379201 |
| ECLASS-6.1      | 27260708 |
| ECLASS-7.0      | 27141152 |
| ECLASS-8.0      | 27141152 |
| ECLASS-9.0      | 27141152 |
| ECLASS-10.1     | 27141152 |
| ECLASS-11.1     | 27141152 |
| ECLASS-12.0     | 27141152 |

|   |  |
|---|--|
| ETIM-5.0  | EC001283                                       |
| customs tariff number                           | 85366990                                       |
| GTIN  | 4048879021586                                  |
| Packaging unit                                  | 1  |
| <b>Electrical data   Supply</b>                 |  |
| Operating voltage AC                            | 125 V  |
| Operating voltage DC                            | 150 V  |
| Operating current max.                          | 2 A  |
| <b>Device protection   Electrical</b>           |  |
| Overvoltage category (EN 60664-1)               | II   |
| <b>Mechanical data   Mounting data</b>          |  |
| Mounting method                                 | geschnappt                                     |
| Suitable for mounting type                      | mounting rail, (EN 60715)                      |
| Height  | 63 mm  |
| Width   | 50 mm  |
| Depth   | 48 mm  |
| Looking techniques                              | Standard UNC 4-40 screw thread bolt (EN 60807) |
| <b>Environmental characteristics   Climatic</b> |  |
| Operating temperature min.                      | -20 °C   |
| Operating temperature max.                      | 70 °C  |