



**LUGS 24 FOR SIGNAL TRANSFER 250V/8 A**

Mounting rail/pluggable spring clamps

24-pole  
Push-In spring clamp terminals

[Link to Product](#)

Illustration

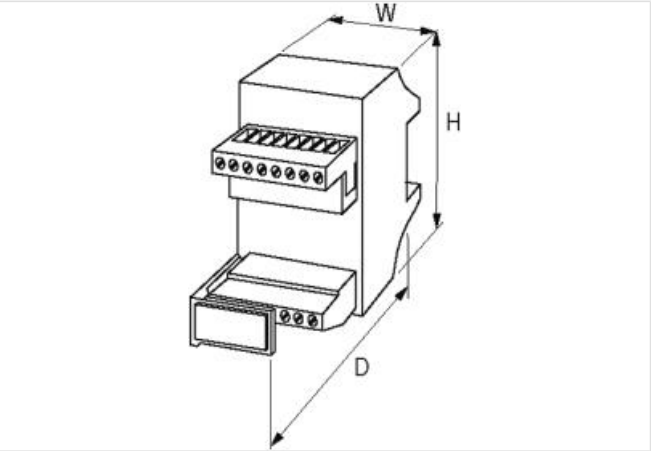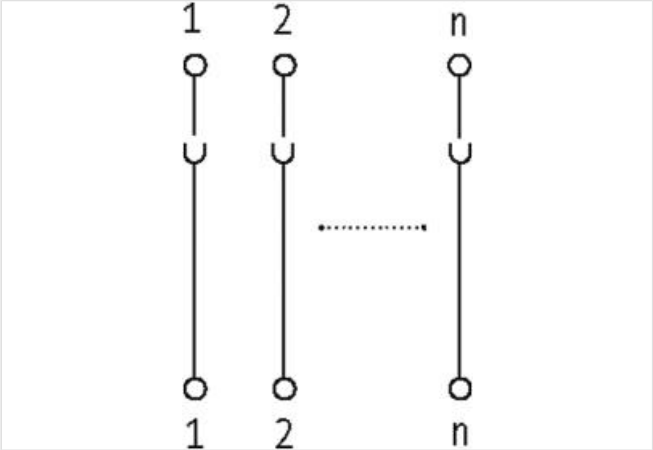

Product may differ from Image



Commercial data	
ECLASS-6.0	27379201
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152
ECLASS-9.0	27141152
ECLASS-10.1	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152

ETIM-5.0	EC001283
customs tariff number	85369010
GTIN	4048879324137
Packaging unit	1

**Electrical data | Supply**

Operating voltage AC	250 V
Operating current max.	8 A

**Installation**

Connection cross section max.	2,5 mm <sup>2</sup>
AWG number	14

**Installation | Connection**

Connection	Spring clamp plug-in terminals
------------	--------------------------------

**Device protection | Electrical**

Overvoltage category (EN 50178)	I
---------------------------------	---

**Mechanical data | Mounting data**

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	75 mm
Width	70 mm
Depth	75 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	60 °C