



MET 1-PHASE CONTROL AND ISOLATION TRANSFORMER

P: 5000VA IN: 230VAC+/- 5% OUT: 230VAC

Single-phase - Control and Isolation Transformers
5000 VA
Spring clamp terminals
Isolation class T 40/B

[Link to Product](#)

Illustration

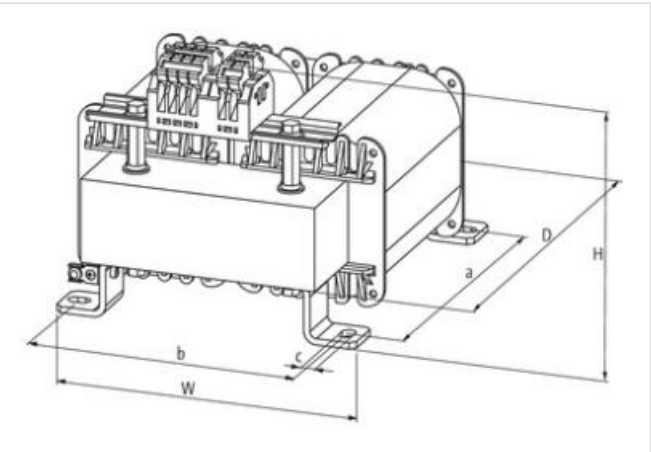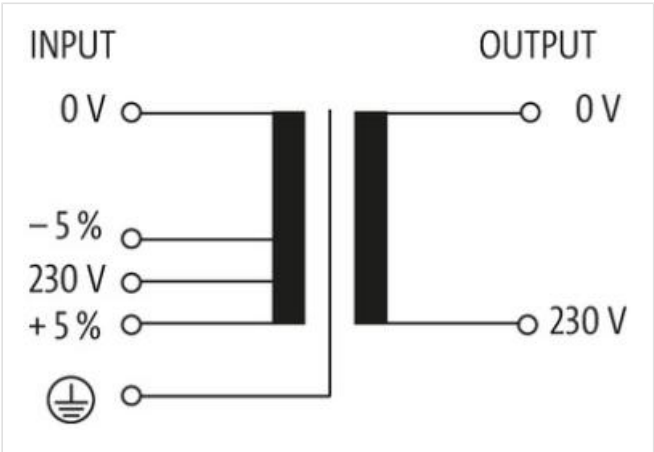

Product may differ from Image



Commercial data	
ECLASS-6.0	27031302
ECLASS-6.1	27031302
ECLASS-7.0	27031302
ECLASS-8.0	27031302
ECLASS-9.0	27031302
ECLASS-10.1	27031302

ECLASS-11.1	27031302
ECLASS-12.0	27031302
ETIM-5.0	EC002486
customs tariff number	85043200
GTIN	4048879066266
Packaging unit	1
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage AC	230 V
Input voltage AC min.	218,5 V
Input voltage AC max.	241,5 V
Current input AC	22,6 A
Max. inrush current	562 A
Short-circuit current	1257 A
Electrical data Output	
Output voltage AC	230 V
Output voltage adjustable	no
Power rating AC max.	5000 VA
Device protection Electrical	
Insulation test voltage input - output	4 kV
Mechanical data Mounting data	
Suitable for mounting type	Long-hole mounting
Mounting dimension a	200 mm
Mounting dimension b	174 mm
Mounting dimension c	9 mm
Height	225 mm
Width	198 mm
Depth	250 mm
Diameter bore	9 mm
Length bore	14 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	40 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
Conformity	
Product standard	EN 61558-1, EN 61558-2-4, EN 62041 category 0