

SIEMENS CONTACTOR SUPPRESSOR

Varistor, 24-48VAC/DC

24 V AC/DC



48 V AC/DC

VDR

For other configurations and voltages, please inquire.

Link to Product

Illustration

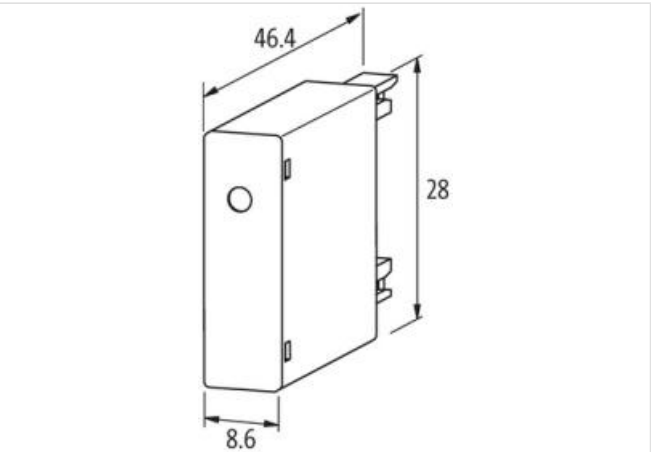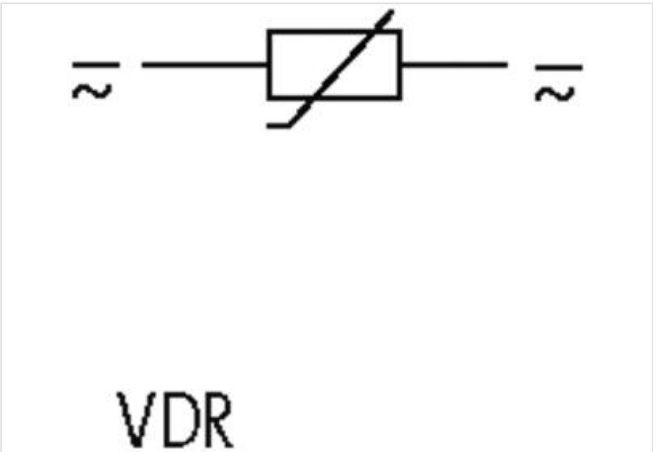

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
customs tariff number	85363010
GTIN	4048879010627
Packaging unit	1

**Compatibility | Compatible with**

Appropriate contactors	3 RT 20.15/16/17/18
------------------------	---------------------

**Electrical data**

Damping factor	1.5× UN
----------------	---------

**Electrical data | Input**

Input voltage AC min.	24 V
Input voltage AC max.	70 V
Input voltage DC min.	24 V
Input voltage DC max.	70 V

**Installation | Connection**

Connection information	Plug contact
------------------------	--------------

**Device protection | Media**

Flame resistance	flame retardant
------------------	-----------------

**Mechanical data | Material data**

Combustibility class housing (UL94)	V-0
Material housing	Plastic

**Mechanical data | Mounting data**

Height	46,4 mm
Width	28 mm
Depth	8,6 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	70 °C