


MIRO SAFE+ HAND 24

24 VDC - 2 N/O contact / 1 N/C contact

6 A
Two hand control

Link to Product

Illustration

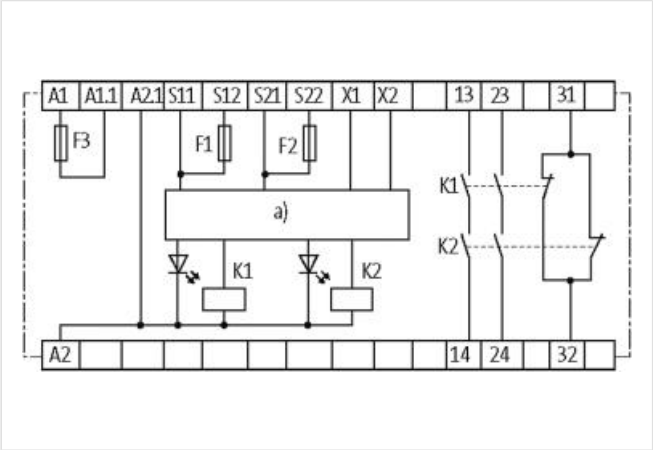

Product may differ from Image



Commercial data	
ECLASS-6.0	27371819
ECLASS-6.1	27371819
ECLASS-7.0	27371819
ECLASS-8.0	27371819
ECLASS-9.0	27371819
ECLASS-10.1	27371819
ECLASS-11.1	27371819
ECLASS-12.0	27371819

ETIM-5.0	EC001449
customs tariff number	85364900
GTIN	4048879367578
Packaging unit	1
Safety codes	
DCavg (EN ISO 13849-1)	99 %
Service life	20 a
Category (EN ISO 13849-1)	4
Performance level (EN ISO 13849-1)	e
SIL (IEC 61508)	3
Electrical data Supply	
Power consumption max.	1,2 W
Electrical data Input	
Input voltage DC	24 V
Input voltage DC min.	21,6 V
Input voltage DC max.	26,4 V
Electrical data Output	
No. of auxiliary contacts	1
No. of alarm outputs	0
No. of safety contacts	2
Utilization category AC-15 (EN IEC 60947-5-1)	6 A @ 230 V
Utilization category DC-13 STOP0 (EN IEC 60947-5-1)	6 A @ 24 V
Auxiliary contacts	31-32
Switching voltage AC max.	250 V
Switching voltage DC max.	250 V
Switching current max.	6 A
Safety contacts	13-14, 23-24
Switching capacity safety contacts STOP0	max. 250 V AC/6 A; min. 10 V AC/10 mA (resist./ind.), at suitable suppression
Device protection	
Condition lifetime	load-dependent
Device protection Electrical	
Electrical lifetime	10000000 Cycles
Device protection Mechanical	
Mechanical endurance	10000000 Cycles
Mechanical data Material data	
Material contact	Ag Sn O
Material properties contact	positively driven, self-cleaning
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	100 mm
Width	22,5 mm
Depth	121 mm
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	85 °C
Connection type 4	

Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	4
PIN 1	A 2
PIN 2	24
PIN 3	14
PIN 4	32
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	4
PIN 1	X 2
PIN 2	S 22
PIN 3	S 21
PIN 4	A 2.1
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	4
PIN 1	X 1
PIN 2	S 12
PIN 3	S 11
PIN 4	A 1.1
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	4
PIN 1	A 1
PIN 2	23
PIN 3	13
PIN 4	31