

**EUROCARD HOLDER**

SKP 32/2-D(a+c)-FK



Spring clamp terminals  
32-pole D (EN 60603)  
Row a, c

With the vertical snap adapter SASA 135 Art.-No. 63900 the holder can be mounted at right-angles on the rail.  
The D2 size is for a card without a front plate.

To insert the card first press down the 2 yellow buttons. Then slide the Eurocard into the guide slots pushing until fully engaged. The card is now locked into position. It can be removed by pressing down on the 2 yellow buttons.

**Link to Product**

**Illustration**

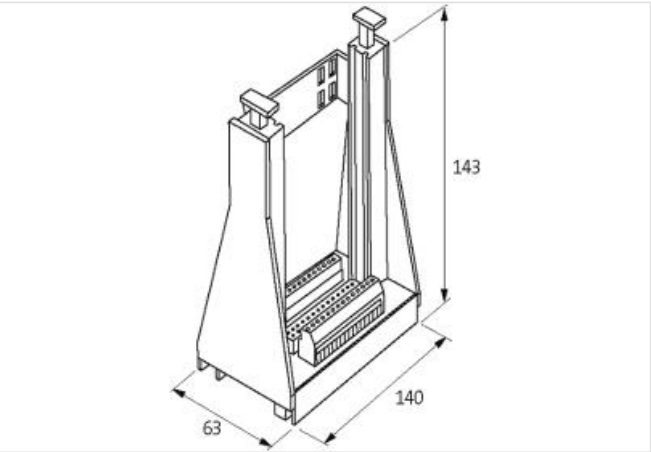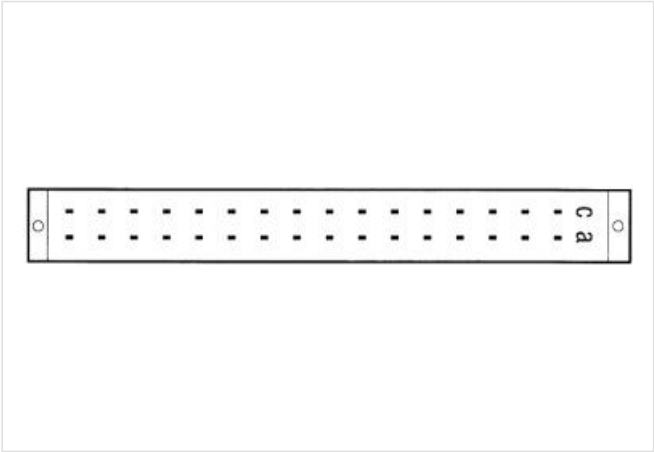

Product may differ from Image



Commercial data	
ECLASS-6.0	27260710
ECLASS-6.1	27260704
ECLASS-7.0	27440402

ECLASS-8.0	27440402
ECLASS-9.0	27460201
ECLASS-10.1	27440402
ECLASS-11.1	27460201
ECLASS-12.0	27460201
ETIM-5.0	EC002780
customs tariff number	85366990
GTIN	4048879038645
Packaging unit	1

**Electrical data | Supply**

Operating voltage AC	250 V
Operating current max.	4 A

**Installation**

Connection cross-section solid max.	4 mm <sup>2</sup>
-------------------------------------	-------------------

**Installation | Pin assignment**

No. of poles	32
--------------	----

**Device protection | Electrical**

Overvoltage category (EN 60664-1)	II
-----------------------------------	----

**Device protection | Media**

Flame resistance	flame retardant
------------------	-----------------

**Mechanical data**

Type of socket connector	D (EN 60603)
--------------------------	--------------

**Mechanical data | Material data**

Material housing	Plastic
------------------	---------

**Mechanical data | Mounting data**

Mounting method	screwed, geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	63 mm
Width	137 mm
Depth	170 mm